


Hospital-Grade Power Cord - NEMA 5-15P to C13 - 15 ft.

Product ID: PXTMG10115

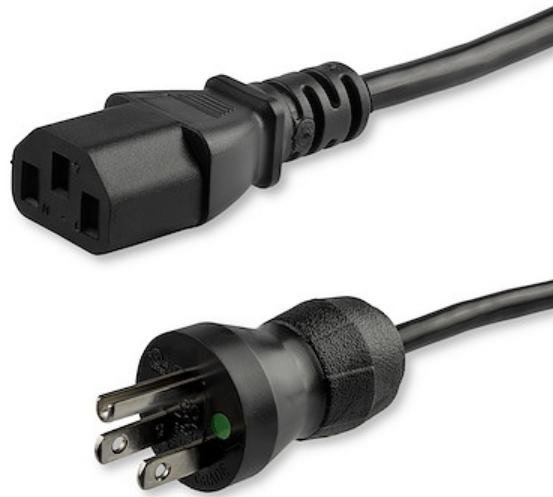

This NEMA 5-15P to C13 power cord features a hospital-grade plug that lets you connect your computer, monitor or other lab equipment to a hospital-grade AC power outlet.

The NEMA 5-15P-HG plug has been tested to UL and CSA standards in order to protect patients and medical staff against faulty ground connections that can be caused by frequent and abrupt connects and disconnects.

The power cord is built to withstand the demands of a hospital environment and is a dependable and safe replacement for worn out or missing power cords.

The PXTMG10115 is backed by a StarTech.com lifetime warranty for guaranteed reliability.

Certifications, Reports and Compatibility

Applications

- Plug your computer, monitor and other medical equipment with a C14 port to a hospital-grade AC power outlet

Features

- Hospital-grade NEMA-5-15P plug marked with the Green Dot
- Safe for use in hospitals and medical environments
- Tested to UL 817 and CAN/CSA C22.2 no. 21-14
- Dependable replacement or spare computer power cord

- Rated to carry 125V at 10A

Hardware

Warranty	Lifetime
Number of Conductors	3
Cable Type	SVT

Connector(s)

Connector A	NEMA 5-15 Power (North America)
Connector B	IEC 60320 C13 Power

Special Notes / Requirements

Note	UL Listed
------	-----------

Power

Input Voltage	125 AC
Input Current	10 A

Physical Characteristics

Color	Black
Connector Style	Straight
Wire Gauge	18 AWG
Cable Length	15.0 ft [4.6 m]
Product Length	15.0 ft [4.6 m]
Product Width	1.3 in [32.5 mm]
Product Height	1.3 in [32.5 mm]
Weight of Product	12.1 oz [344.0 g]

Packaging Information

Package Length	10.6 in [27.0 cm]
Package Width	5.1 in [13.0 cm]



Package Height	1.2 in [30.0 mm]
Shipping (Package) Weight	12.4 oz [351.0 g]

What's in the Box

Included in Package	NEMA 5-15P to C13 power cord
---------------------	------------------------------

****Product appearance and specifications are subject to change without notice.***

