


2-Post 24U Heavy-Duty Wall Mount Network Rack, 19" Open Frame Server Rack with Adjustable Depth, Wall Mount Data Rack for IT / AV / Patch Panel / Computer Equipment - Cage Nuts and Screws Included

Product ID: RACK-24U-20-WALL-OA

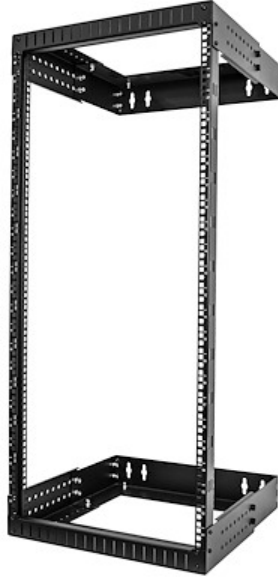

The RACK-24U-20-WALL-OA 24U Open Frame Wall Mount Equipment Rack with Adjustable Depth is a high-quality, sturdy relay rack solution that is easy to assemble and install into any environment.

The open rack features an adjustable depth ranging from 12-20 inches to accommodate larger data, network, and telecommunications devices. With a maximum depth of 20 inches, this rack allows for mounting of shelves and other accessories with enough clearance at the back for cable management. The open-frame design help to keep your equipment cool and easily accessible from different angles. The wall mounting holes are positioned 12 and 16 inches apart (center to center) providing a convenient and effecting anchoring, making it suitable for mounting on virtually any wall surface or construction framework.

This 24U rack includes M6 square cage nuts and M6 screws to save you the hassle of sourcing separate mounting hardware for your equipment. This rack can be mounted to the wall in a server room, data closet, or office expanding your valuable floor space.

The RACK-24U-20-WALL-OA is backed for 5-years by StarTech.com, including free lifetime 24/5 multi-lingual technical assistance.

Certifications, Reports and Compatibility

Applications

Features

- **ADJUSTABLE DEPTH:** This 2-post 24U 19 inch open frame network rack is EIA/ECA-310 compliant and has an adjustable depth (12-20in / 30.5-50.8cm); Data rack is ideal for AV / Audio / IT / computer equipment, servers, switches, patch panels, and PDUs
- **HEAVY DUTY:** Durable rack features a vertical rail made of 2.0mm SPCC cold-rolled steel and a weight capacity of up to 200lbs/90kg; Its design supports unobstructed airflow to help keep your equipment cool and easy to install with access to all sides
- **EFFICIENT FLAT PACK SHIPPING:** The IT rack ships flat packed with ISTA-6 certified packaging (assembly required) to ensure hassle-free installations with complete & undamaged delivery; Comprehensive assembly instructions included
- **HARDWARE INCLUDED:** The open post wall mount server rack includes a complete set of M6 square cage nuts, M6 screws and plastic washers to securely mount all of your equipment in the rack
- **THE IT PRO'S CHOICE:** Designed and built for IT Professionals, this 24U wall mounted network rack is backed for 5-years, including free lifetime 24/5 multi-lingual technical assistance

Hardware

| | |
|-----------------------|---------------------------------|
| Warranty | 5 Years |
| Wallmountable | Yes |
| Rack Type | 2-Post |
| Frame Type | Open Frame |
| U Height | 24U |
| Special Features | Easy Assembly Wall-Mountable |
| Mounting Rail Profile | G-Shape |
| Mounting Hole Types | Square (For Cage Nut) |
| Industry Standards | EIA/ECA-310-E |

Performance

| | |
|-----------------|------------------|
| Weight Capacity | 198.4 lb [90 kg] |
|-----------------|------------------|

Physical Characteristics

| | |
|-----------------------|-------------------|
| Color | Black |
| Construction Material | Steel |
| Product Length | 20.0 in [50.8 cm] |

| | |
|------------------------|--------------------|
| Product Width | 19.8 in [50.4 cm] |
| Product Height | 46.2 in [117.3 cm] |
| Weight of Product | 35.3 lb [16.0 kg] |
| Maximum Mounting Depth | 20.0 in [50.8 cm] |

Packaging Information

| | |
|---------------------------|-------------------|
| Package Quantity | 1 |
| Package Length | 4.0 ft [1.2 m] |
| Package Width | 16.5 in [42.0 cm] |
| Package Height | 6.3 in [16.0 cm] |
| Shipping (Package) Weight | 44.8 lb [20.3 kg] |

What's in the Box

| | |
|-----------------------|-------------------------------|
| Included in Package | 2 - Front Horizontal Brackets |
| | 2 - Rear Horizontal Brackets |
| | 2 - Vertical Brackets |
| | 96 - M6 Cage Nuts |
| | 96 - M6 Cage Screws |
| | 96 - Plastic Washers |
| | 16 - M5x12mm Assembly Screws |
| | 24 - M8x16mm Bolts |
| | 24 - #8 Flat Washers |
| 1 - Quick-Start Guide | |

****Product appearance and specifications are subject to change without notice.***