

1U 20" High Resolution Folding Rackmount LCD Console for 19in Rack

Product ID: RACKCONS2001




The RACKCONS2001 1U 20-inch High Resolution Folding Rack Mount LCD Console (for 19-inch racks) provides total KVM control right from your server rack, with a complete keyboard, monitor, mouse, and audio control point integrated into a space-efficient 1U of rack/cabinet space.

This durable and compact KVM Rack Console offers the largest (20.1-inches) and highest resolution (up to 1600x1200) TFT-LCD monitor available in a 1U rackmount design. When not in use, it can be folded and slid back into the server rack on sturdy mounting rails (included).

With the included cables, the LCD console can be connected to virtually any multi-port KVM switch for control of multiple servers/computers, providing a scalable solution that lets you determine the type of KVM switch to use. Plus, the console supports connection to PS/2, USB, VGA and DVI systems, accommodating both legacy and cutting edge computers.

Backed by a StarTech.com 2-year warranty and free lifetime technical support.

Certifications, Reports and Compatibility

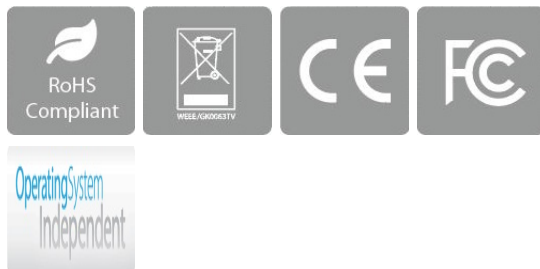

Applications

- Rack mount LCD Console solution for server applications requiring high resolutions
- Centralized control of dozens of PCs and servers if used with optional KVM
- Improving the internal space efficiency of existing cabinets
- Managing cabinet mounted servers and KVM switches

Features

- High resolution 20.1in LCD display
- VGA and DVI video input support
- Compatible with both USB and PS/2 PCs and KVMs
- Built-in speakers
- OSD menu(On Screen Display) for LCD display functions
- Lockable LCD display for security
- Tempered glass LCD panel
- Durable Heavy duty steel design
- Bright Active Matrix TFT Display

Hardware

Warranty	2 Years
U Height	1U
Front Door Key Lock	Yes
Audio	No
Display Size	20in
Panel Type	Active Matrix TFT LCD
KVM Ports	1
PC Interface	USB and PS/2
PC Video Type	DVI+VGA
Number of Monitors Supported	1

	Rack-Mountable	Yes
	Daisy-Chain	Yes
<hr/>		
Performance		
	On-Screen Display	Yes
	IP Control	No
	Maximum Analog Resolutions	1600 x 1200 (UXGA)
	Aspect Ratio	Standard (4:3)
	Response Time	16ms
	Contrast Ratio	700:1
	Brightness	300 cd/m
	Color Depth	24-bit, 16.7M colors (Truecolor)
	Pixel Pitch Support	0.255 x 0.255 mm
	Viewing Angle	178 (H), 178 (V)
	Maximum Number of Users	1
	MTBF	60,000 Hours
<hr/>		
Connector(s)		
	Host Connectors	1 - 3.5 mm Mini-Jack (3 Position)
		1 - DVI-I (29 pin)
		2 - PS/2 (6 pin, Mini-DIN)
		2 - USB 2.0 Type-A (4 pin, 480Mbps)
		1 - VGA (15 pin, High Density D-Sub)
<hr/>		
Software		
	OS Compatibility	OS independent; No software or drivers required
<hr/>		
Power		
	Power Source	AC Adapter Included
	Input Voltage	110V-240V AC

Output Voltage	18 DC
Output Current	3.3A
Center Tip Polarity	Positive
Plug Type	N

Environmental

Operating Temperature	0C to 50C (32F to 122F)
Storage Temperature	-20C to 60C (-4F to 140F)
Humidity	10~90% RH

Physical Characteristics

Color	Black
Material	Heavy Duty Steel
Product Length	24.0 in [60.8 cm]
Product Width	17.7 in [44.9 cm]
Product Height	1.7 in [4.4 cm]
Weight of Product	34.2 lb [15.5 kg]
Maximum Mounting Depth	39.4 in [100 cm]
Minimum Mounting Depth	30.1 in [76.4 cm]

Packaging Information

Package Length	21.7 in [55 cm]
Package Width	31.7 in [80.6 cm]
Package Height	7.9 in [20 cm]
Shipping (Package) Weight	47.0 lb [21.3 kg]

What's in the Box

Included in Package	1 - 1U 20.1in LCD Rack Console Drawer
	1 - Mounting Rails - Set

- 1 - 3.5mm Audio cable
- 1 - PS2 and VGA Console cable
- 2 - 6 ft USB A to A Male Male cables
- 1 - 6 ft DVI Cable
- 1 - Set of Keys
- 1 - Set of mounting screws
- 1 - Power Cord
- 1 - Power Adapter
- 1 - User Manual

**Warranty
Information**

Warranty	2 Years
----------	---------

**Product appearance and specifications are subject to change without notice.*