

6ft (2m) Power Extension Cord, Right Angle NEMA 5-15P to NEMA 5-15R, 13A 125V, 16AWG, Computer Power Extension Cord, Flat Extension Cord, AC Outlet Extension Cable

Produkt-ID: RFX-6F-POWER-CORD




Configure the NEMA 5-15 power connections in a server room, reduce cable strain for safe and efficient power connections behind office furniture, and extend the length of bulky power cords.

The extension cord features a low-profile right-angled NEMA 5-15 plug. This reduces cable strain and increases the amount of airflow when connecting to a NEMA 5-15 receptacle that is situated behind a cabinet or a desk within a high-density server rack in a data center. Extend any NEMA 5-15 power cord (e.g., for a computer, display, server PDU/UPS, etc.).

The right-angle power cord enables access to previously blocked receptacles, located on power strips, surge protectors, or wall outlets. Since the cable is situated to the side of the outlet, bulky plugs will no longer impede access to nearby receptacles.

This product is backed for life, including free lifetime 24/5 multi-lingual technical assistance.

Zertifikate Berichte und Kompatibilität

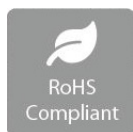

Anwendungen

Merkmale

- **AC POWER EXTENSION CORD:** This 6ft (1.8m) 16AWG AC power extension cord with Right-Angle NEMA 5-15P and NEMA 5-15R connectors is suitable for workstations/home offices | Indoor use only | Rated to carry 125V at 13A
- **PERFORMANCE AND SAFETY:** UL listed components | Fully molded strain relief connectors for durability | Fire Rating: VW-1 | 3 Conductor extension cord made with 100% copper wire | This power extension cord is available in 1ft and 3ft
- **SPECS:** 6ft (1.8m) AC Power Cord | Right-Angle NEMA 5-15P to NEMA 5-15R | 16AWG | 125V 13A (Max) | Jacket Type: SJT | Jacket Material: PVC | Black | Temperature Range: 14°F to 95°F (-10°C to 35°C) | Cable Outer Diameter: 0.33in (8.4mm)
- **COMPATIBILITY:** PC Power Extension Cord NEMA 5-15P works with North American outlets | Extend a 3-prong power connection from your desktop computer, server, or printer | Replacement power supply cable/cord
- **THE IT PRO'S CHOICE:** Designed and built for IT Professionals, this extension cord is backed for life, including free lifetime 24/5 multi-lingual technical assistance

Hardware

Garantiebestimmungen	Lifetime
Anzahl von Leitern	3
Steckverbinderplatten	Nickel
Typ der Kabelummantelung	PVC - Polyvinyl Chloride
Feuerwiderstandssklasse	Klasse VW-1e
Kabeltyp	SJT

Steckverbinder

Steckverbinder A	1 - NEMA 5-15 Strom (Nordamerika)
Steckverbinder B	1 - NEMA 5-15 Strom (Nordamerika)

Strom

Eingangsspannung	125 AC
Eingangsstrom	13 A

Umgebungsbedingungen

Betriebstemperatur	-10 to 35°C (14 to 95°F)
Lagertemperatur	-20 to 60°C (-4 to 140°F)
Feuchtigkeit	20 bis 80 % Relative Luftfeuchtigkeit

Physische Eigenschaften

Farbe	Schwarz
Steckverbinderart	Right Angle to Straight
Drahtstärke	16 AWG
Außendurchmesser des Kabels	0.3 in [8.5 mm]
Produktlänge	6.0 ft [1.8 m]
Produktbreite	1.0 in [2.6 cm]
Produkthöhe	1.4 in [3.5 cm]
Produktgewicht	9.2 oz [262.0 g]

Verpackungsinformationen

Paketmenge	1
Paketlänge	9.2 in [23.3 cm]
Paketbreite	3.0 in [7.7 cm]
Pakethöhe	1.9 in [4.9 cm]
Versandgewicht (Verpackung)	9.4 oz [266.0 g]

Verpackungsinhalt

Im Paket enthalten	1 - Netzkabelverlängerung
--------------------	---------------------------

Garantieinformationen

Warranty	Lifetime
----------	----------

* Größe, Aussehen und Spezifikationen sind Änderungen ohne vorherige Ankündigung vorbehalten.