


12U 19in server rack kast met scharnierende stalen roosterdeur - muur monteerbaar

Productcode: RK1219WALHM

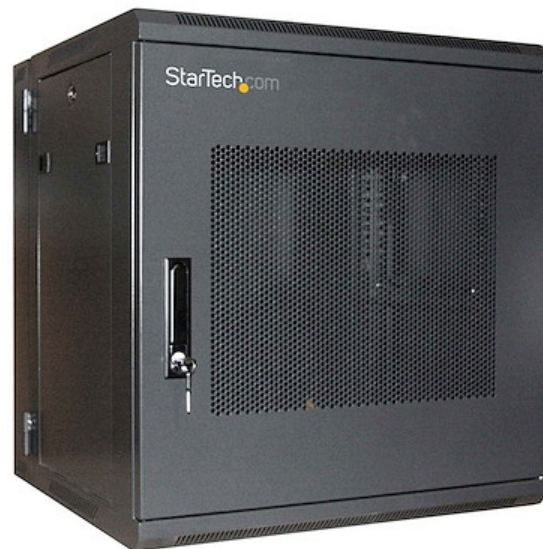

This 12U Server Rack/Cabinet offers a durable solution for mounting valuable server equipment, routers, switches and other networking equipment while saving space and hassle.

The sturdy 12U rack cabinet features a high quality steel design and a vented, steel mesh door to help keep rack mounted equipment safe and cool.

A suitable addition to any server room, wiring closet, manufacturing area, warehouse or locale where networking equipment requires an added level of protection, the 12U rack cabinet accommodates 19in wall mount devices (19" depth) and features a rear-hinged design that makes it easier to access cabling and device ports.

Our 12U Rack Cabinet is designed for guaranteed reliability to ensure a stable rack mount platform for valuable equipment and backed by Lifetime Warranty.

Certificaties, rapporten en compatibiliteit

Toepassingen

- Mounting standard 19 in. networking equipment in exposed or unsecure locations

Eigenschappen

- Unique hinged design swings open for easy access to your equipment
- Cable pass-through at rear of cabinet

- Fan mounts for optional additional cooling
- Removable side panels with lock.
- Sturdy steel design
- Steel mesh door for added security

Hardware

Garantiebeleid	Lifetime
Wandmonteerbaar	Ja
Rack type	Met 4 stijlen
Type frame	Gesloten kast
U-hoogte	12U
Speciale functies	Verstelbare montagerails Aardingslip(pen) Volledig gemonteerd geleverd wandmonteerbaar
Montagerailprofiel	L-Shape
Mounting Hole Types	Vierkant (voor kooimoer)
Industriestandaarden	EIA/ECA-310-E

Prestaties

Weight Capacity	132.6 lb [60 kg]
-----------------	------------------

Fysieke eigenschappen

Kleur	Zwart
Type voordeur	Staalgaas
Kenmerken deur voorkant	Beveiligd sleutelslot met verwijderbare voordeur
Type zijpaneel	Staal

Kenmerken zijpanelen	Beveiligd sleutelslot met verwijderbare zijpanelen
Type achterdeur	Staal
Kenmerken deur achterkant	Veiligheidsslot met sleutel

Product Measurements

Interne breedte	22.0 in [56 cm]
Interne diepte	20.6 in [52.2 cm]
Lengte product	21.7 in [55 cm]
Breedte product	23.5 in [59.7 cm]
Hoogte product	25.0 in [63.5 cm]
Gewicht product	55.5 lb [25.1 kg]
Maximale montagediepte	15.4 in [39.2 cm]
Minimale montagediepte	2.7 in [68 mm]

Verpakkingsinformatie

Plat verpakt (montage vereist)	Nee
Package Length	27.6 in [70 cm]
Package Width	26.2 in [66.5 cm]
Package Height	26.1 in [66.2 cm]
Verzendgewicht (verpakt)	62.2 lb [28.1 kg]

Wat wordt er meegeleverd

Meegleverd	Black Hinged Cabinet Set of Keys
------------	-------------------------------------



M6 schroeven

M6 kooimoeren

* Uitvoering en specificaties van het product zijn zonder aankondiging vatbaar voor wijzigingen.

