


## 12U 19in Hinged Wall Mount Server Rack Cabinet w/ Steel Mesh Door

**Product ID:** RK1219WALHM

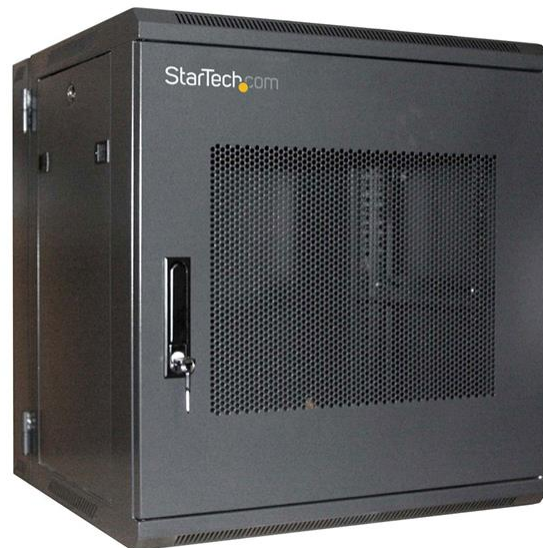

This 12U Server Rack/Cabinet offers a durable solution for mounting valuable server equipment, routers, switches and other networking equipment while saving space and hassle.

The sturdy 12U rack cabinet features a high quality steel design and a vented, steel mesh door to help keep rack mounted equipment safe and cool.

A suitable addition to any server room, wiring closet, manufacturing area, warehouse or locale where networking equipment requires an added level of protection, the 12U rack cabinet accommodates 19in wall mount devices (19" depth) and features a rear-hinged design that makes it easier to access cabling and device ports.

Our 12U Rack Cabinet is designed for guaranteed reliability to ensure a stable rack mount platform for valuable equipment and backed by Lifetime Warranty.

### **Certifications, Reports and Compatibility**

### **Applications**

- Mounting standard 19 in. networking equipment in exposed or unsecure locations

### **Features**

- Cable pass-through at rear of cabinet
- Fan mounts for optional additional cooling
- Removable side panels with lock.

- Sturdy steel design
- Steel mesh door for added security
- Unique hinged design swings open for easy access to your equipment

---

#### Hardware

Warranty	Lifetime
Wallmountable	Yes
Rack Type	4-Post
Frame Type	Aluminum
U Height	12U
Special Features	Adjustable Mounting Rails
	Grounding Lug(s)
	Ships Fully Assembled
	Wall-Mountable
Mounting Rail Profile	L-Shape
Mounting Hole Types	Square (For Cage Nut)
Industry Standards	EIA/ECA-310-E

---

#### Performance

Weight Capacity	132.6 lb [60 kg]
-----------------	------------------

---

#### Physical Characteristics

Color	Black
Front Door Construction	Steel Mesh
Front Door Features	Secure Key Lock with Removable Front Door
Side Panel Construction	Steel
Side Panel Features	Secure Key Lock with Removable Side Panels
Rear Door Construction	Steel
Rear Door Features	Secure Key Lock

---

**Product Measurements**

Internal Width	22.0 in [56 cm]
Internal Depth	20.6 in [52.2 cm]
Product Length	21.7 in [55 cm]
Product Width	23.5 in [59.7 cm]
Product Height	25.0 in [63.5 cm]
Weight of Product	55.5 lb [25.1 kg]
Maximum Mounting Depth	15.4 in [39.2 cm]
Minimum Mounting Depth	2.7 in [68 mm]

---

**Packaging Information**

Flat Pack (Assembly Required)	No
Package Length	27.6 in [70 cm]
Package Width	26.2 in [66.5 cm]
Package Height	26.1 in [66.2 cm]
Shipping (Package) Weight	62.2 lb [28.1 kg]

---

**What's in the Box**

Included in Package	Black Hinged Cabinet
	Set of Keys
	M6 Screws
	M6 Cage Nuts

---

***\*Product appearance and specifications are subject to change without notice.***

