

Refurbished 12U 19in Wall Mounted Server Rack Cabinet

Product ID: RK1219WALLR



Refurbished cabinets may have minor scratches and dents similar to photos.

This refurbished 12U 19in Wall Mounted Server Rack Cabinet is perfect for safely mounting routers, switches, media converters, and other networking equipment. Features a sturdy steel design and a vented tempered glass door keep your equipment safe and cool.

Suited for server rooms, wiring closets, manufacturing areas, warehouses, or anywhere where networking equipment needs to be protected.


Every refurbished server rack includes complete mounting hardware and accessories as intended with the original (non-refurbished) product, and are provided in the original packaging. Refurbished units may have small scratches in the paint on the metal casing, but all other components are as new. Backed by a 90-day replacement warranty,.

Certifications, Reports and Compatibility

Applications

- Mounting standard 19 in. networking equipment in exposed or insecure locations
- Data centers
- Industrial control centers
- Telecommunication closets
- Audio/Visual control centers

Features

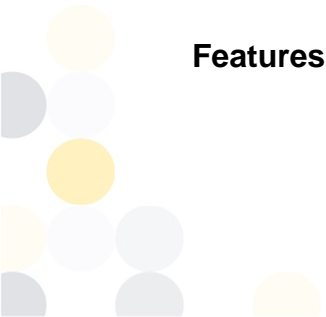

- Cable pass-through at rear of cabinet
- Fan mounts for optional additional cooling
- Removable side panels with lock.
- Sturdy steel design
- Tempered, vented, lockable glass front door

Hardware

| | |
|-----------------------|--|
| Warranty | None |
| Wallmountable | Yes |
| Rack Type | 4-Post |
| Frame Type | Steel |
| U Height | 12U |
| Special Features | Ships Fully Assembled Wall-Mountable Adjustable Mounting Rails Grounding Lug(s) |
| Mounting Rail Profile | L-Shape |
| Fan Options | Two Optional Fans: 120 mm |
| Mounting Hole Types | Square (For Cage Nut) |
| Industry Standards | EIA/ECA-310-E |

Performance

| | |
|-----------------|------------------|
| Weight Capacity | 132.6 lb [60 kg] |
|-----------------|------------------|

Physical Characteristics

| | |
|-------------------------|--|
| Color | Beige |
| Front Door Construction | Steel with Glass/Acrylic Window |
| Front Door Features | Secure Key Lock with Reversible and Removable Front Door |
| Side Panel Construction | Steel |

| | |
|------------------------|--|
| Side Panel Features | Secure Key Lock with Removable Side Panels |
| Rear Door Construction | Steel |

Product Measurements

| | |
|------------------------|-------------------|
| Internal Width | 23.4 in [59.5 cm] |
| Internal Depth | 23.3 in [59.1 cm] |
| Product Length | 24.2 in [61.4 cm] |
| Product Width | 23.7 in [60.1 cm] |
| Product Height | 25.1 in [63.7 cm] |
| Weight of Product | 66.3 lb [30.0 kg] |
| Maximum Mounting Depth | 21.7 in [55 cm] |
| Minimum Mounting Depth | 0.4 in [11 mm] |

Packaging Information

| | |
|-------------------------------|-------------------|
| Flat Pack (Assembly Required) | No |
| Package Length | 27.6 in [70.0 cm] |
| Package Width | 27.2 in [69.1 cm] |
| Package Height | 25.8 in [65.6 cm] |
| Shipping (Package) Weight | 68.5 lb [31.0 kg] |

What's in the Box

| | |
|---------------------|-------------------------------------|
| Included in Package | 19in Cabinet |
| | Package of Cab screws and Cage Nuts |
| | Keys |

**Product appearance and specifications are subject to change without notice.*

