


12U 19" Wall Mount Network Rack - 12" Deep 2 Post Open Frame Server Room Rack for Data/AV/IT/ Communication/Computer Equipment/Patch Panel w/Cage Nuts & Screws 200lb Capacity

**Product ID:** RK12WALLO

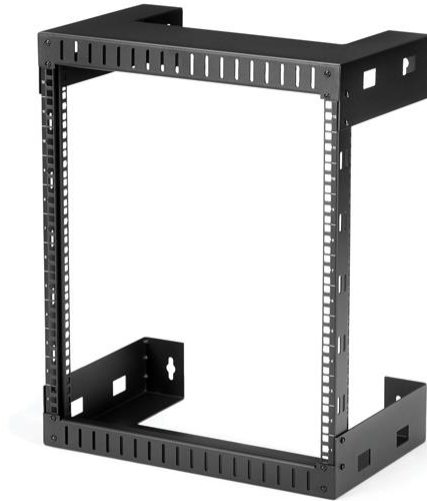

This open-frame wall-mount server rack provides 12U of storage, allowing you to save space and stay organized. The equipment rack can hold up to 198 lb. (90 kg).

The network rack is 12 in. (30.4 cm) deep, so it's perfect for smaller spaces. It's easy to assemble and features mounting holes that are spaced 16 in. apart, making it suitable for mounting on almost any wall, based on common wall-frame stud spacing. The wall-mount rack comes in a flat-pack which makes it easy to transport and reduces shipping costs.

You can mount the open-frame rack where space is limited, such as on a server room wall, office, or above a doorway, to expand your workspace and ensure your equipment is easy to access.

By having an open frame the server rack provides passive cooling to equipment. Additionally, the open frame provides easy access and configurability to your equipment, allowing you to maximize productivity.

The RK12WALLO is backed by a StarTech.com 5-year warranty and free lifetime technical support.

## Certifications, Reports and Compatibility

### Applications

- Perfect for installing network switches out of the way and high up on a wall in a branch office, warehouse, or superstore location
- Ideal for small and medium businesses requiring small rack solutions dispersed throughout the organization
- Mount audio/video broadcast or distribution components

## Features

- **HEAVY DUTY:** This heavy duty 2 post open frame rack supports unobstructed airflow & is easy to install with a durable design made from SPCC cold-rolled steel with support for up to 200lbs of equipment
- **STURDY & CONVENIENT:** 12U 19" Open Frame wall mount network rack with 12" mounting depth is EIA/ECA-310 compatible & supports like patch panels, shelves and unmanaged switches
- **EASY ASSEMBLY:** The rack ships flat packed with ISTA-6 certified packaging to ensure complete and undamaged delivery and also features comprehensive assembly instructions
- **ACCESSORIES INCLUDED:** The wall mount server room/ computer/communication/AV/IT equipment rack includes a complete set of 60 screws and cage nuts to securely mount all of your equipment in the rack
- **LIFETIME WARRANTY:** StarTech.com offers 24 hour technical support and has been the choice of IT professionals for 30 years, conducting thorough compatibility and performance testing on all our products

---

### Hardware

Warranty	5 Years
Wallmountable	Yes
Rack Type	2-Post
Frame Type	Open Frame
U Height	12U
Special Features	U-Markings Wall-Mountable Easy Assembly
Mounting Rail Profile	G-Shape
Mounting Hole Types	Square (For Cage Nut)
Industry Standards	EIA/ECA-310-E

---

### Performance

Weight Capacity	198.9 lb [90 kg]
-----------------	------------------

---

### Physical Characteristics

Color	Black
-------	-------



Construction Material      Steel

**Product Measurements**

Product Length	12.0 in [30.5 cm]
Product Width	19.8 in [50.4 cm]
Product Height	25.2 in [64.1 cm]
Weight of Product	19.1 lb [8.6 kg]
Maximum Mounting Depth	12.0 in [30.5 cm]

**Packaging Information**

Flat Pack (Assembly Required)	Yes
Package Length	26.4 in [67.0 cm]
Package Width	20.9 in [53.0 cm]
Package Height	5.1 in [13.0 cm]
Shipping (Package) Weight	24.3 lb [11.0 kg]

**What's in the Box**

Included in Package	M6 Screws
	M6 Cage Nuts
	Washers
	Assembly Screws
	Vertical Rails
	Horizontal Brackets
	User Manual

***\*Product appearance and specifications are subject to change without notice.***

