


12U 19" Wall Mount Network Rack - Adjustable Depth 12-20" 2 Post Open Frame Server Room Rack for AV/Data/ IT Communication/Computer Equipment/Switch w/Cage Nuts & Screws

Product ID: RK12WALLOA

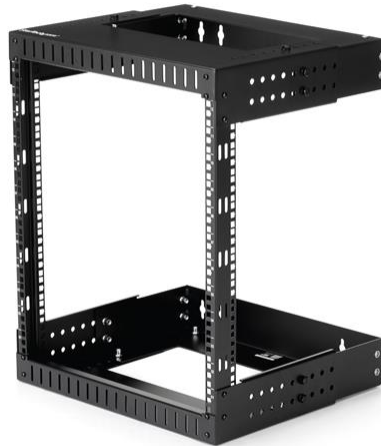

This open-frame wall-mount server rack provides 12U of storage, helping you to save space and stay organized. The equipment rack features an adjustable depth and can hold a total of up to 198 lb. (90 kg).

With adjustable depth to as low as 12 in. (30.4 cm) this network rack is perfect for smaller spaces. It's easy to assemble and features wall-mounting holes that are spaced 12 and 16 in. apart, making it suitable for mounting on almost any wall, based on North American wall-frame stud-spacing standards. The wall-mount rack comes in a flat-pack, which makes it easy to transport and saves you money on shipping.

The open-frame rack adjusts from 12 to 20 in. (30.4 to 50.8 cm) to accommodate larger data, network, and telecommunication devices. The above-average depth also gives you the option to mount shelves and other accessories.

When space is limited you can mount the open-frame rack on a server room wall, office, or above a doorway, to expand your workspace and ensure your equipment is easy to access.

The rack's open frame design ensures passive cooling for your rack-mounted equipment. Additionally, the open frame provides easy access to your equipment and makes it easier to configure mounted devices, which saves you time.

The RK12WALLOA is backed by a StarTech.com 5-year warranty and free lifetime technical support.

Certifications, Reports and Compatibility

Applications

- Perfect for installing network switches out of the way and high up on a wall in a branch office, warehouse, or superstore location

- Mount audio/video broadcast or distribution components
- Ideal for small and medium businesses requiring small rack solutions dispersed throughout the organization

Features

- **DURABLE & ADJUSTABLE:** This adjustable 12U 19" open frame wall mount network rack is EIA/ECA-310 compatible w/ 12-20" mounting depth supports most network switches like Cisco 2960
- **HEAVY DUTY:** This heavy duty 2 post open frame rack supports unobstructed airflow and is easy to install w/ a durable design made from SPCC cold-rolled steel with support for up to 200lbs of equipment
- **CERTIFIED PACKAGING:** The rack ships flat packed with ISTA-6 certified packaging to ensure complete and undamaged delivery and also features comprehensive assembly instructions
- **ACCESSORIES INCLUDED:** The wall mount server room/ computer/communication/AV/IT equipment rack includes a complete set of 60 screws & cage nuts to securely mount all of your equipment in the rack
- **LIFETIME WARRANTY:** StarTech.com offers 24 hour technical support and has been the choice of IT professionals for 30 years, conducting thorough compatibility and performance testing on all our products

Hardware

Warranty	5 Years
Wallmountable	Yes
Rack Type	2-Post
Frame Type	Open Frame
U Height	12U
Special Features	Adjustable Mounting Rails
	U-Markings
	Wall-Mountable
	Easy Assembly
Mounting Rail Profile	L-Shape
Mounting Hole Types	Square (For Cage Nut)
Industry Standards	EIA/ECA-310-E

Performance

Weight Capacity	198.9 lb [90 kg]
-----------------	------------------

Physical Characteristics

Color	Black
Construction Material	Steel

Product Measurements

Product Length	20.1 in [51.0 cm]
Product Width	19.8 in [50.3 cm]
Product Height	25.2 in [64.0 cm]
Weight of Product	32.3 lb [14.6 kg]
Maximum Mounting Depth	19.9 in [50.5 cm]

Packaging Information

Flat Pack (Assembly Required)	Yes
Package Length	26.4 in [67.0 cm]
Package Width	20.9 in [53.0 cm]
Package Height	5.1 in [13.0 cm]
Shipping (Package) Weight	37.6 lb [17.0 kg]

What's in the Box

Included in Package	Vertical Rails
	Front Horizontal Brackets
	Rear Horizontal Brackets
	M6 Cage Nuts
	M6 Screws
	Plastic Washers
	Assembly Screws



Flat Washers

Bolts

User Manual

****Product appearance and specifications are subject to change without notice.***

