

## 6U 19in Wall Mount Server Rack Cabinet with Acrylic Door

**Product ID:** RK619WALL



StarTech.com

The RK619WALL Wall Mounted 6U Server Rack/Cabinet can be fastened to most types of walls and features a sturdy, compact design that can be positioned almost anywhere without wasting valuable floor space. This TAA compliant product adheres to the requirements of the US Federal Trade Agreements Act (TAA), allowing government GSA Schedule purchases.

This equipment rack offers 6U of storage space and is designed to accommodate 19-inch (wide) servers, networking and telecom equipment. The rack features a 12cm fan, with ventilation positioned above and below the front panel glass door, helping to keep dust out of the rack while ensuring a cool operating environment for your valuable equipment.

To ensure optimum security and prevent tampering with the enclosed equipment, the cabinet/rack features a lockable, smoked acrylic front door that can be removed entirely or installed to open to the left or right as needed.


Backed by a StarTech.com Lifetime warranty.

## Certifications, Reports and Compatibility

### Applications

- Install rack equipment over doorways, or in tight spaces like server closets
- Mount networking and telecommunication equipment to the wall
- Securely protect and wall mount sensitive rack mountable equipment

### Features

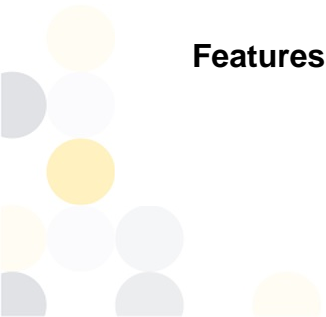

- Lockable acrylic door with a large viewing area
- Compact wall mount design and rugged steel construction
- TAA compliant for GSA Schedule purchases
- Vented panels with a 120mm cooling fan
- Large side and bottom cable routing holes with grommets

---

#### Hardware

Warranty	Lifetime
Wallmountable	Yes
Rack Type	2-Post
Frame Type	Enclosed Cabinet
U Height	6U
Special Features	Ships Fully Assembled Wall-Mountable
Mounting Rail Profile	L-Shape
Fan Options	One Fan Included: 120 mm + One Optional Fan: 120 mm
Mounting Hole Types	Square (For Cage Nut)
Industry Standards	EIA/ECA-310-E

---

#### Performance

Airflow Rate	82 CFM
Audible Noise	38 dBA @ 1 Meter
Weight Capacity	110.5 lb [50 kg]

---

#### Physical Characteristics

Color	Black
Front Door Construction	Steel w/ Window
Front Door Features	Secure Key Lock with Removable Front Door
Side Panel Construction	Steel



---

**Product Measurements**

Internal Width	21.7 in [55 cm]
Internal Depth	14.7 in [37.5 cm]
Product Length	15.7 in [39.8 cm]
Product Width	22.1 in [56.1 cm]
Product Height	13.1 in [33.2 cm]
Weight of Product	22.9 lb [10.4 kg]
Maximum Mounting Depth	14.7 in [37.5 cm]

---

**Packaging Information**

Flat Pack (Assembly Required)	No
Package Length	27.0 in [68.5 cm]
Package Width	18.3 in [46.5 cm]
Package Height	18.4 in [46.8 cm]
Shipping (Package) Weight	29.3 lb [13.3 kg]

---

**What's in the Box**

Included in Package	6U Wallmount Cabinet
	Set of Keys
	M5 Screws
	M5 Cage Nuts

---

***\*Product appearance and specifications are subject to change without notice.***

