

3,5" SATA Festplattengehäuse - eSATA / USB 3.0 - Wechselfestplattenschacht

Produkt-ID: S351BMU33ET



This eSATA enclosure for 3.5 in. SATA HDDs is perfect for those who require quick and easy access to important data and files. It is ideal if you need easy access to your data or need to back up, archive, or recover data and multimedia content.

Multiple connectivity options

The external hard drive enclosure supports USB 3.0, also known as USB 3.2 Gen 1, and eSATA, allowing you to access your data through your preferred interface. For fast performance and efficient data transfers, when connected through eSATA, the enclosure supports full SATA III transfer speeds - up to 6Gbps.

For universal compatibility, the enclosure can be connected through USB 3.0 with transfer speeds up to 5Gbps, plus support for UASP. The HDD enclosure lets you connect a SATA III (6Gbps) hard drive, but is also compatible with SATA I and II.


Ease of use

The hard drive enclosure allows you to swap drives in and out as needed with the trayless design. The enclosure is simple to set up and easy to use, with its plug-and-play functionality. It's also equipped with an LED light to indicate power and activity.

Compact design works great with your Mac or PC

With a sleek, compact style, this hard drive enclosure is a perfect desktop companion for your Mac or PC. It occupies minimal space, and features a fanless design that keeps the enclosure quiet so you to focus on what's important.

Zertifikate Berichte und Kompatibilität

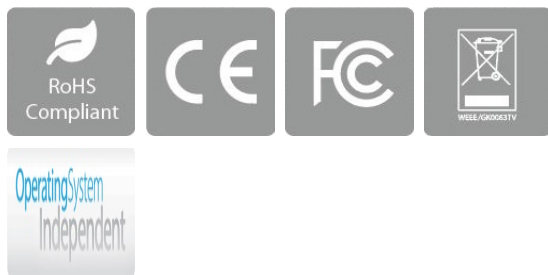

Anwendungen

- Retrieve data from an old SATA drive, or turn the unused drive into additional external storage space
- Hot-swap drives using a single enclosure instead of having to swap separate enclosures
- Upgrade from a USB 2.0 drive enclosure to faster USB 3.0
- Share large files between computers quickly and securely without a network connection
- Perfect for creative professionals, office, government, and medical personnel, sales executives, teachers, and research scientists who require access to important data and files

Merkmale

- **VERSATILE FUNCTIONALITY:** This eSATA enclosure for 3.5 in. SATA HDDs is perfect if you need quick and easy access to your data or need to back up, archive, or recover data and multimedia content
- **MAXIMUM COMPATIBILITY:** The universal 3.5" SATA hard drive enclosure can be connected through USB 3.0 with transfer speeds up 5Gbps; The HDD enclosure is also compatible with SATA I and II
- **EASY TO USE:** The external hard drive enclosure allows you to swap drives in and out as needed with the trayless design; The enclosure has plug-and-play functionality
- **SAVES SPACE:** With a sleek, compact style, this trayless hard drive enclosure, occupies minimal space, and features a fanless design that keeps the enclosure quiet so you to focus on what's important
- **THE IT PRO'S CHOICE:** Designed and built for IT professionals, this eSATA / USB 5Gbps enclosure is backed for 2 years, including free lifetime 24/5 multi-lingual technical assistance

Hardware

Garantiebestimmungen 2 Years

Lüfter

Nein

Schnittstelle	USB 3.0 & eSATA
Bustyp	USB 3.0 & eSATA
Anzahl von Laufwerken	1
Laufwerkgröße	3.5in
Laufwerktyp	SATA
Laufwerkinstallation	Entnehmbar
Anzahl von internen 3,5-Zoll-Schächten	1
Chipset-ID	ASMedia - ASM1153E ASMedia - ASM1456

Leistung

Max. Datenübertragungsrate	6 Gbps
Typ und Rate	USB 3.0 – 5 Gbit/s
UASP-Unterstützung	Ja
TRIM Support	Ja
4Kn Support	Ja
S.M.A.R.T. Support	Ja
Typ und Rate	SATA III (6 Gbps)
Max. Laufwerkskapazität	Currently tested with up to 10TB 7200 RPM hard drives
Hot Swap-Funktion	Ja
Einbauvorgänge	50,000 cycles

Steckverbinder

Laufwerksteckverbinder	1 - SATA Daten und Strom, Combo (7+15-polig)
Hostanschlüsse	1 - USB 3.2 Typ-B (9-polig, Gen 1, 5Gbit/s)

1 - eSATA (7-polig, Daten)

Software

Betriebssystemkompatibilität	OS independent; No software or drivers required
------------------------------	---

Spezielle Hinweise/Anforderungen

Hinweis	Windows 7 and earlier Windows versions do not support TRIM with USB to SATA devices.
---------	--

Anzeiger

LED-Anzeiger	1 - Power/Activity
--------------	--------------------

Strom

Stromversorgung	Mit Netzadapter
Eingangsspannung	100 - 240 AC
Eingangsstrom	0.8A
Ausgangsspannung	12V DC
Ausgangsstrom	2000mA
Polarität der Mittelspitze	Positiv
Steckertyp	M
Stromverbrauch	24

Umgebungsbedingungen

Betriebstemperatur	0°C to 50°C (32°F to 122°F)
Lagertemperatur	-20°C to 55°C (-4°F to 131°F)
Feuchtigkeit	5% to 65%

Physische Eigenschaften

Farbe	Schwarz
Gehäusetyp	Stahl

Produktlänge	8.3 in [21.0 cm]
Produktbreite	5.3 in [13.4 cm]
Produkthöhe	1.5 in [3.8 cm]
Produktgewicht	18.4 oz [520.0 g]

Verpackungsinformationen

Paketmenge	1
Paketlänge	6.3 in [15.9 cm]
Paketbreite	9.6 in [24.4 cm]
Pakethöhe	4.1 in [10.3 cm]
Versandgewicht (Verpackung)	2.3 lb [1.0 kg]

Verpackungsinhalt

Im Paket enthalten	1 - drive enclosure
	1 - enclosure stand
	1 - USB 3.0 cable
	1 - eSATA cable
	1 - Netzadapter (NA)
	1 - quick-start guide

Garantieinformationen

Warranty	2 Jahre
----------	---------

* Größe, Aussehen und Spezifikationen sind Änderungen ohne vorherige Ankündigung vorbehalten.