

3.5in Silver USB 2.0 to SATA External Hard Drive Enclosure

Product ID: SAT3510U2V




This External Hard Drive Enclosure lets you install a 3.5in SATA hard drive for connection to a computer using USB 2.0 - a cost-effective storage solution for a wide variety of applications including file and application sharing between desktop and laptop computers, data archiving, or simply backing up existing hard drives to preserve data security. Large capacity drives (tested with up to 4TB) can be used to greatly enhance your computer's storage/backup capabilities.

Designed with modern computer systems in mind, the USB 2.0 SATA hard drive enclosure is compatible with the IT industry's newest 3.5in SATA (SATA, SATA II, SATA III) drives and features a sleek, sturdy aluminum casing that looks terrific next to any MAC or PC system.

The enclosure is compatible with a broad range of Windows operating systems, Mac OS 9.0 and up and Linux, as well as Apple's Mac OS X Leopard operating system - including its breakthrough automatic "Time Machine" backup feature.

Certifications, Reports and Compatibility

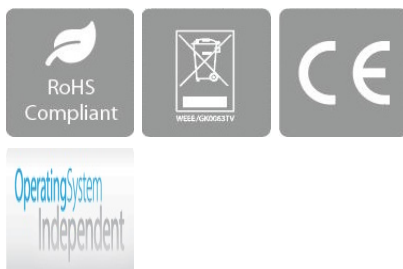

Applications

- Create a fast, portable external storage solution for desktops, laptops or netbooks

- Add-on extra storage to almost any USB enabled computer system
- Backup important data to an external storage device
- Share large files between computers quickly and securely without a network
- Retrieve data from old SATA drive, or turn the unused drive into additional external storage space

Features

- High Speed USB 2.0 host interface, with supported transfer rates up to 480 Mbps
- Power/Activity LED indicator
- Light-weight and durable aluminum chassis
- Compatible with SATA revision 1/2/3 (1.5/3.0/6.0 Gbps) hard drives
- Supports 3.5" form factor SATA hard drives
- Plug-and-Play and Hot-Swap compatible

Hardware

Warranty	2 Years
Fan(s)	No
Interface	USB 2.0
Number of Drives	1
Drive Size	3.5in
Compatible Drive Types	SATA
Drive Installation	Fixed
Chipset ID	SunplusIT - SPIF215A

Performance

Maximum Data Transfer Rate	480 Mbps
Type and Rate	USB 2.0 - 480 Mbit/s
UASP Support	No
Type and Rate	SATA II (3 Gbps)

Hardware Raid Supported No

Max Drive Capacity Currently tested with up to 4TB 5400 RPM hard drives

Connector(s)

Drive Connectors 1 - SATA Data & Power Combo (7+15 pin)

Host Connectors 1 - USB B (4 pin)

Software

OS Compatibility OS independent; No software or drivers required

Indicators

LED Indicators 1 - Solid Green -Power status
Blinking Green - Read/Write Drive Activity

Power

Power Source AC Adapter Included

Input Voltage 115V AC

Output Voltage 12V DC

Output Current 2A

Center Tip Polarity Positive

Plug Type M

Physical Characteristics

Color Silver

Material Aluminum

Product Length 7.6 in [19.3 cm]

Product Width 1.2 in [3.1 cm]

Product Height 4.4 in [11.3 cm]

Weight of Product 11.5 oz [325 g]

Packaging Information

Package Length 10.3 in [26.2 cm]

Package Width	3.5 in [89 mm]
Package Height	7.6 in [19.4 cm]
Shipping (Package) Weight	1.8 lb [0.8 kg]

What's in the Box

Included in Package	1 - 3.5in SATA HDD Enclosure
	1 - Plastic Stand
	1 - USB Cable
	1 - Screw Kit
	1 - Power Adapter
	1 - Instruction Manual

Warranty Information

Warranty	2 Years
----------	---------

****Product appearance and specifications are subject to change without notice.***