


6in SATA Serial ATA Cable

Produkt ID: SATA6

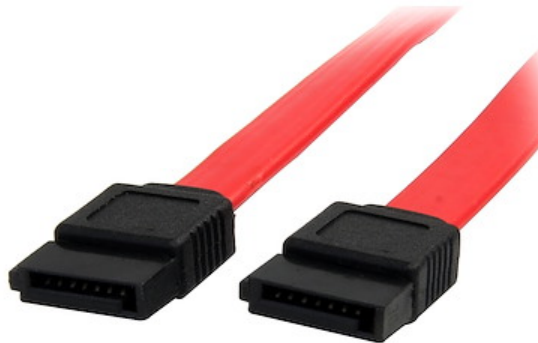

The SATA6 Serial ATA Cable features two 7-pin data receptacles and supports full SATA 3.0 bandwidth of up to 6Gbps when used with SATA 3.0 compliant drives.

Featuring a low profile, yet durable construction, the flexible design improves airflow and reduces clutter in your computer case, helping to keep the case clean and cool.

Constructed of only top quality materials and designed for optimum performance and reliability this 6" SATA cable is backed by our lifetime warranty.

Certifikat, rapporter och kompatibilitet

Användning

- Installing Serial ATA hard drives, and DVD drives in Small Form Factor computer cases
- Server and storage subsystem applications
- High-end workstation drive installations
- Connections to SATA Drive Arrays

Funktioner

- Supports full SATA 3.0 6Gbps bandwidth

- Compatible with both 3.5" and 2.5" SATA hard drives
- Provides 6" in cable length

Hårdvara

Garantipolicy	Lifetime
Antal ledare	7
Kabelmanteltyp	PVC - Polyvinyl Chloride

Prestanda

Typ och hastighet	SATA III (6 Gbps)
-------------------	-------------------

Kontakt(er)

Connector A	SATA (7-stifts, data)
Connector B	SATA (7-stifts, data)

Miljö

Drifttemperatur	20°C to 80°C (68°F to 176°F)
Förvaringstemperatur	24°C to 25°C (75.2°F to 77°F)
Luftfuktighet	50% relative humidity

Utseende

Färg	Röd
Kontakttyp	Utan lås
Tråddimension	26 AWG (0.404 mm)
Kabellängd	6.0 in [15.2 cm]
Produktlängd	5.0 in [12.8 cm]
Produktbredd	0.8 in [20.0 mm]
Produkt höjd	32.3 in [82.1 cm]
Produktvikt	0.2 oz [6.0 g]

Förpackning



Package Length	5.0 in [12.8 cm]
Package Width	8.6 in [22.0 cm]
Package Height	0.0 in [0.6 mm]
Fraktvikt (förpackning)	0.4 oz [11.0 g]

Vad det är i lådan

Ingår i paketet	6in SATA Serial ATA Cable
-----------------	---------------------------

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.

