

eSATA USB to SATA External HDD Docking Station for 2.5 or 3.5in

Product ID: SATDOCKU2EEU




This eSATA/USB to SATA External HDD Docking Station provides immediate, swappable access to any 2.5in or 3.5in SATA (SATA, SATA II, SATA III) hard drive or solid state drive - without having to mount the hard drive, or install it in an enclosure! Large capacity drives (tested with up to 4TB 3.5" and 1TB 2.5" drives) can be used to greatly enhance your computer's storage/backup capabilities.

Simply connect this docking station to a computer using either eSATA or USB 2.0, and it's as simple as inserting your 2.5in or 3.5in SATA hard drive into the dock whenever needed.

A perfect solution for data recovery, drive imaging, and testing centers, or any environment that requires fast access to uninstalled/archived drives, the SATA HDD Dock supports plug and play installation on most operating systems. Plus, the HDD docking station supports data transfer speeds of up to 3 Gbps (using eSATA) and 480Mbps (using USB 2.0) between host and dock - ensuring effortless data dumps, backups and hassle-free file transfers. Double the value of this hard drive docking station, using a SATA to IDE hard drive adapter (SAT2IDEADP), which enables you to use any 2.5 or 3.5in IDE hard drive in a SATA hard drive dock slot.

Certifications, Reports and Compatibility

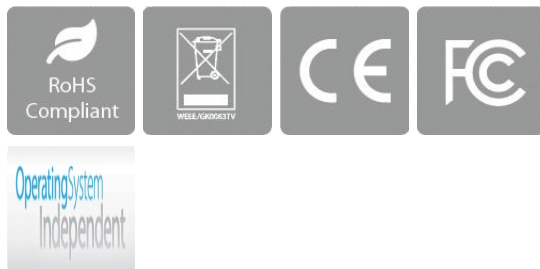

Applications

- Access spare or removed 2.5/3.5" drives quickly to retrieve data from
- Data recovery specialists who need quick access to drives for imaging
- Backup data quickly to an external drive for archiving
- Technicians who regularly test or benchmark different hard drives and need to swap between them
- Take advantage of new laptops and desktops with USB 3.0 connectivity

Features

- Top slot loading design with drive door
- Power/Activity LED indicator
- SATA revision 2 compliant eSATA host interface, with support for transfer rates up to 3 Gbps
- High Speed USB 2.0 compliant host interface, with support for transfer rates up to 480 Mbps
- Compatible with SATA revision 1/2/3 (1.5/3.0/6.0 Gbps) drives
- Supports 2.5" or 3.5" form factor hard drives (HDD) and solid state drives (SSD)
- Plug-and-Play and Hot-Swap compatible
- Compact desktop style form factor

Hardware

Warranty	2 Years
Fan(s)	No
Interface	USB 2.0 & eSATA
Number of Drives	1
Drive Size	2.5in & 3.5in
Compatible Drive Types	SATA
Chipset ID	JMicron - JM20336

Performance

Type and Rate	USB 2.0 - 480 Mbit/s
UASP Support	No
Type and Rate	SATA II (3 Gbps)

	Max Drive Capacity	Currently tested with up to 4TB 5400 RPM 3.5" hard drives and 1TB 5400 RPM 2.5" hard drive
	Insertion Rating	15, 000 cycles
Connector(s)		
	Drive Connectors	1 - SATA Data & Power Combo (7+15 pin)
	Host Connectors	1 - eSATA (7 pin, Data)
		1 - USB B (4 pin)
Software		
	OS Compatibility	OS independent; No software or drivers required
Indicators		
	LED Indicators	1 - Power/Activity
Power		
	Power Source	AC Adapter Included
	Input Voltage	230 AC
	Output Voltage	12V DC
	Output Current	2A
	Center Tip Polarity	Positive
	Plug Type	M
Physical Characteristics		
	Color	Black
	Material	Plastic
	Product Length	5.5 in [14 cm]
	Product Width	3.6 in [9.1 cm]
	Product Height	2.2 in [5.5 cm]
	Weight of Product	7.8 oz [221 g]

Packaging Information

Package Length	6.5 in [16.4 cm]
Package Width	3.6 in [92 mm]
Package Height	6.8 in [17.2 cm]
Shipping (Package) Weight	1.9 lb [0.8 kg]

What's in the Box

Included in Package	1 - SATA hard drive docking station
	1 - eSATA Cable
	1 - USB Cable
	1 - Power Adapter
	1 - Instruction Manual

****Product appearance and specifications are subject to change without notice.***