

USB to SATA External HDD Docking Station for 2.5 or 3.5in Hard Drive

Produkt ID: SATDOCKU2EU




This external hard drive docking station functions as a SATA HDD dock - providing full, instant access to any 2.5in or 3.5in SATA (SATA, SATA II, SATA III) hard drive or solid state drive - without having to mount the hard drive in a computer or install it in an enclosure! Large capacity drives (tested with up to 4TB 3.5" and 1TB 2.5" drives) can be used to greatly enhance your computer's storage/backup capabilities.

Simply connect the HDD docking station to a host computer through USB 2.0, then insert a SATA hard drive into the dock whenever needed. To uninstall or swap the hard drive, just remove it from the dock!

The USB to SATA External HDD Dock Adapter supports plug and play hard drive installation on most operating systems, and offers data transfer speeds of up to 480Mbps - providing a convenient alternative to external hard drive enclosures and saving the time needed to prepare the drive for conventional installation. Double the value of this hard drive docking station, using a SATA to IDE hard drive adapter (SAT2IDEADP), which enables you to use any 2.5 or 3.5in IDE hard drive in a SATA hard drive dock slot.

Certifikat, rapporter och kompatibilitet

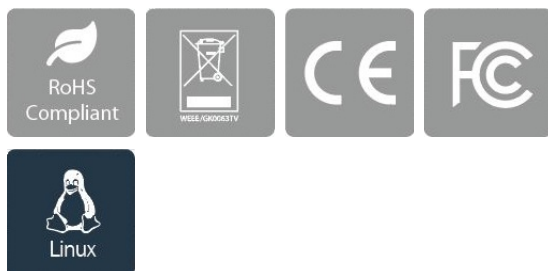

Användning

- Access spare or removed 2.5/3.5" drives quickly to retrieve data from
- Data recovery specialists who need quick access to drives for imaging
- Backup data quickly to an external drive for archiving
- Technicians who regularly test or benchmark different hard drives and need to swap between them
- Take advantage of new laptops and desktops with USB 3.0 connectivity

Funktioner

- Top slot loading design with drive door
- Power/Activity LED indicator
- High Speed USB 2.0 compliant host interface, with support for transfer rates up to 480 Mbps
- Compatible with SATA revision 1/2/3 (1.5/3.0/6.0 Gbps) drives
- Supports 2.5" or 3.5" form factor hard drives (HDD) and solid state drives (SSD)
- Plug-and-Play and Hot-Swap compatible
- Compact desktop style form factor

Hårdvara

Garantipolicy	2 Years
Fläkt(ar)	Nej
Gränssnitt	USB 2.0
Antal enheter	1
Enhetsstorlek	2.5in & 3.5in
Enhetsstyp	SATA

Prestanda

Maximal dataöverföringshastighet	480 Mbps
----------------------------------	----------

	Typ och hastighet	USB 2.0 - 480 Mbit/s
	UASP-stöd	Nej
	Typ och hastighet	SATA II (3 Gbps)
	Maximal enhetskapacitet	Currently tested with up to 4TB 5400 RPM 3.5" hard drives and 1TB 5400 RPM 2.5" hard drive
Kontakt(er)	Enhetskontakter	1 - SATA data- & ström-kombo (7+15-stifts)
	Värdkontakter	1 - USB B (4-stifts)
Mjukvara	OS-kompatibilitet	Windows 98SE/ME/2000/2003/XP/VISTA x64/x86, Mac OS G4 10.0 and up, G5 10.3.9+, Linux RedHat 9 & Fedora FC4/FC5
Indikatorer	LED-indikatorer	1 - Power/Activity
Ström	Strömkälla	AC-adapter medföljer
	Inspänning	230 AC
	Utspänning	12V DC
	Utström	2A
	Polaritet på mittpol	Positiv
	Kontakttyp	M
Utseende	Färg	Svart
	Kabinetttyp	Av plast
	Produktlängd	5.5 in [14 cm]
	Produktbredd	3.6 in [9.1 cm]
	Produkthöjd	2.2 in [5.5 cm]

	Produktvikt	7.8 oz [220 g]
Förpackning		
	Förpackningsantal	1
	Paketets längd	6.7 in [17 cm]
	Paketets bredd	3.6 in [92 mm]
	Paketets höjd	6.8 in [17.3 cm]
	Fraktvikt (förpackning)	1.1 lb [0.5 kg]
Vad det är i lådan		
	Ingår i paketet	1 - SATA hard drive docking station
		1 - USB Cable
		1 - Power Adapter
		1 - Instruction Manual
Warranty Information		
	Warranty	2 År

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.