

4-Bay Hard Drive Docking Station for 2.5"/3.5" SSDs and HDDs - eSATA/USB 3.0 to SATA (6Gbps)

Product ID: SDOCK4U33E



Dock and swap up to four drives from your laptop or desktop computer simultaneously, using a single eSATA or USB port. This 4-bay docking station gives you large data capacity and fast file transfers with support for SATA I, II and III (up to 6Gbps).

Access multiple drives with this quad-bay docking station. It saves you valuable time every day by giving you independent access to four 2.5" or 3.5" SATA hard drives or solid-state drives. Ideal for data recoveries, imaging or backups, it lets you access four drives at once, instead of connecting your drives one by one.

You can connect the docking station through either eSATA or USB. For fast performance and efficient data transfers when connected through eSATA, the docking station supports full SATA III transfer speeds - up to 6Gbps. For universal compatibility, the dock can be connected through USB 3.0 with transfer speeds up to 5Gbps, plus it supports UASP for enhanced performance.

For IT technicians or business professionals who need to check files or test different drives, the dock lets you hot-swap your drives in and out as needed. Its top-loading, toaster-style design with drive ejection buttons make the dock easy to use while two silent cooling fans help to dissipate heat to maintain an optimum operating temperature.


With support for SATA I, II and III high-capacity drives (tested up to 6TB), this docking station is compatible with virtually any 2.5" and 3.5" SATA SSD or HDD drive.

The docking station also works with 2.5" and 3.5" IDE hard drives, mSATA drives and M.2 drives using a compatible StarTech.com adapter: IDE hard drives: Use StarTech.com adapter SAT2IDEADP SATA to 2.5in or 3.5in IDE Hard Drive Adapter for HDD DocksmSATA drives: Use StarTech.com adapter SAT32MSAT257 mSATA SSD to 2.5in SATA Adapter ConverterM.2 drives: Use StarTech.com adapter SAT32M225 M.2 NGFF SSD to 2.5in SATA Adapter Converter

The quad-bay dock is OS independent, which ensures a quick and easy setup. It also features a compact design and small footprint that makes it easy to tuck into your workspace.

The SDOCK4U33E is backed by a StarTech.com 2-year warranty and free lifetime technical support.

Certifications, Reports and Compatibility

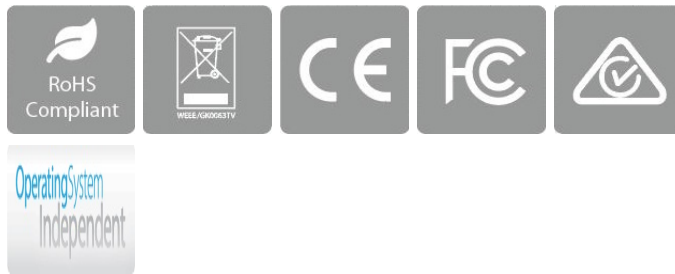

Applications

- System builders and IT specialists can gain quick access to drives for imaging
- Back up data quickly to an external drive for archiving
- Transfer data from one drive to another
- Technicians can test or benchmark multiple drives with ease
- Backup important data and easily take the drive to an offsite location for safekeeping

Features

- Access up to four SATA drives simultaneously, in a single docking station
- Supports both 2.5" and 3.5" HDDs and SSDs
- USB 3.0 or high-speed eSATA host connection with port multiplier
- Supports SATA I, II and III (up to 6Gbps)
- Top-loading design with drive doors and drive ejection buttons
- UASP support for enhanced performance
- Dual 60mm cooling fans
- Backward compatible with USB 2.0 and 1.x
- Plug-and-play and hot-swap compatible

Hardware

Warranty	2 Years
Fan(s)	Yes

Fans	2 - 60 mm
Interface	USB 3.0 & eSATA
Number of Drives	4
Drive Size	2.5in & 3.5in
Compatible Drive Types	SATA
Drive Installation	Removable
Fan Bearing Type	Sleeve Bearing
Chipset ID	JMicron - JMS567 JMicron - JBM575

Performance

Maximum Data Transfer Rate	5Gbps
Type and Rate	USB 3.0 - 5 Gbit/s
UASP Support	Yes
Type and Rate	SATA III (6 Gbps)
Port Multiplier	Yes
Max Drive Capacity	Currently tested with up to 6TB
Hot Swap Capability	Yes
MTBF	30000

Connector(s)

Drive Connectors	4 - 22 pin SATA Data & Power Combo Receptacle
Host Connectors	1 - USB 3.2 Type-B (9 pin, Gen 1, 5Gbps) 1 - eSATA (7 pin, Data) Plug

Software

OS Compatibility	OS independent; No software or drivers required
------------------	---

Indicators

LED Indicators	4 - Power
----------------	-----------

4 - Activity

Power

Power Source	AC Adapter Included
Input Voltage	100 - 240 AC
Input Current	2.0A
Output Voltage	12V DC
Output Current	6500mA
Plug Type	4-pin DIN
Power Consumption (In Watts)	78

Environmental

Operating Temperature	5C to 35C (41F to 95F)
Storage Temperature	-20C to 50C (-4F to 122F)
Humidity	20% ~ 80% RH

Physical Characteristics

Color	Black
Material	Plastic
Product Length	11.2 in [28.5 cm]
Product Width	6.8 in [17.2 cm]
Product Height	3.4 in [8.7 cm]
Weight of Product	2.2 lb [1.0 kg]

Packaging Information

Package Quantity	1
Package Length	13.5 in [34.3 cm]
Package Width	8.5 in [21.5 cm]
Package Height	6.7 in [17.0 cm]

Shipping (Package) Weight	5.3 lb [2.4 kg]
------------------------------	-----------------

What's in the Box

Included in Package	1 - 4-bay hard drive docking station
	1 - universal power adapter
	4 - power cords (NA/UK/EU/AU)
	1 - USB A to B cable
	1 - eSATA cable
	1 - quick install guide

****Product appearance and specifications are subject to change without notice.***