


MSA Uncoded SFP+ Module - 10GBASE-LRM - 10GbE Multi Mode Fiber (MMF) Optic Transceiver - 10GE Gigabit Ethernet SFP+ - LC 200m - 1310nm - DDM

Product ID: SFP10GBLRMST

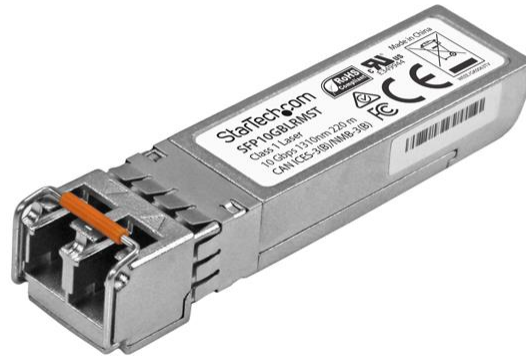

The SFP10GBLRMST is an MSA compliant fiber SFP transceiver that's designed, programmed and tested to work with 10GBASE-LRM compatible MSA switches and routers. The SFP+ transceiver module supports a maximum distance of up to 220 m (721 ft.) and delivers dependable 10 GbE connectivity over fiber cabling. **Technical Specifications:**

- Wavelength: 1310 nm
- Maximum Data Transfer Rate: 10 Gbps
- Type: Multi Mode Fiber
- Connection Type: LC Connector
- Maximum Transfer Distance: 220 m (721 ft.)
- Power Consumption: Less than 1 Watt
- DDM: Yes

This SFP+ fiber module is hot-swappable, making upgrades and replacements seamless by minimizing network disruptions.

All StarTech.com SFP & SFP+ transceiver modules are backed by a lifetime warranty and free lifetime multilingual technical support. StarTech.com offers a wide variety of SFP modules and direct-attach SFP Cables, providing the convenience and reliability you need to ensure dependable network performance.

Certifications, Reports and Compatibility

Applications

- Replace defective or damaged SFP+ modules
- Expand your network to remote segments

Features

- **TESTED FOR COMPATIBILITY:** Hot-swappable in MSA Compliant routers and switches; DDM support reports the transceiver's status to most SNMP network management tools.
- **WORKS WITH MSA COMPLIANT SWITCHES:** Works with switch models from Ubiquiti, D-Link, Netgear, Supermicro, TP-Link and more that accept uncoded modules
- **100% MSA UNCODED SFP+ TRANSCEIVER:** Designed, programmed and tested to work with compatible MSA Compliant switches and routers to deliver dependable 10GbE connectivity
- **TECHNICAL SPECS:** 10GBASE-LRM 10Gbps Multi Mode (MMF) LC Connector 1310nm Digital Diagnostic Monitoring (DDM) Distances up to 200m (656ft)
- **LIFETIME WARRANTY:** Backed by a lifetime warranty on the life of the module itself and not the life of your switch; our modules won't void your OEM warranty and supported by our Tech Advisors 5/24

Hardware

Warranty	Lifetime
Compatible Brand	MSA Compliant
WDM	No
Industry Standards	IEEE 802.3ae 10GBASE-LRM

Performance

Maximum Data Transfer Rate	10 Gbps
Max Transfer Distance	220 m (721 ft.)
Type	Multi Mode
Wavelength	1310nm
Fiber Operating Mode	Full-Duplex
DDM	Yes
Compatible Networks	10 Gbps



Power Consumption (In Watts) < 1 W

Connector(s)

Local Unit Connectors Fiber Optic LC Duplex

Environmental

Operating Temperature 0C to 70C (32F to 158F)

Storage Temperature -40C to 85C (-40F to 185F)

Humidity 5~95% RH

Physical Characteristics

Product Length 2.3 in [58.4 mm]

Product Width 0.5 in [13.9 mm]

Product Height 0.5 in [12.6 mm]

Weight of Product 0.8 oz [23.0 g]

Packaging Information

Package Length 4.7 in [12.0 cm]

Package Width 3.5 in [90.0 mm]

Package Height 1.2 in [30.0 mm]

Shipping (Package) Weight 1.9 oz [53.0 g]

What's in the Box

Included in Package SFP+ transceiver

**Product appearance and specifications are subject to change without notice.*

