


## Dell EMC SFP-1G-BX40-U Compatible SFP Module - 1000BASE-BX-U - 10 GbE Gigabit Ethernet BiDi Fiber (SMF) (SFP1GBX40UES)

**Product ID:** SFP1GBX40UES

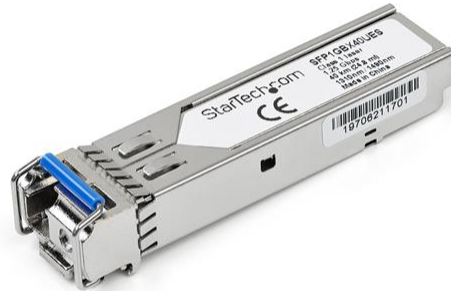

The SFP1GBX40UES is a Dell EMC SFP-1G-BX40-U compatible upstream fiber SFP transceiver which pairs with StarTech.com's SFP1GBX40DES. They are designed, programmed and tested to work with 1000Base-BX40 compatible Dell EMC switches and routers. The SFP transceiver module supports a maximum distance of up to 40 km (24.8 mi) and delivers dependable 1 GbE connectivity over fiber cabling.

### Technical Specifications:

- Wavelength: 1310nmTx/1490nmRx
- Maximum Data Transfer Rate: 1000 Mbps (1 Gbps)
- Type: Single Mode Fiber
- Connection Type: LC Connector
- Maximum Transfer Distance: 40 km (24.8 mi)
- Power Consumption: < 1.6W
- DDM: Yes

This SFP fiber module is hot-swappable, making upgrades and replacements seamless by minimizing network disruptions.

All StarTech.com SFP & SFP+ transceiver modules are backed by a lifetime warranty and free lifetime multilingual technical support. StarTech.com offers a wide variety of SFP modules and direct-attach SFP Cables, providing the convenience and reliability you need to ensure dependable network performance.

## Certifications, Reports and Compatibility

## Applications

## Features

- **100% DELL EMC SFP-1G-BX40-U COMPATIBLE:** 1 Gigabit Ethernet BiDi Fiber Single Strand SFP designed, programmed and tested to work with compatible Dell EMC switches and routers to deliver dependable 1GbE connectivity
- **INCREASE BANDWIDTH ON EXISTING INFRASTRUCTURE:** This 10 Gigabit Ethernet bi-directional WDM SFP+ transceiver module sends and receives over a single strand of fiber optic cable instead of two
- **TECHNICAL SPECS:** 1000BASE-BX-U 1Gbps 10G Bi-Directional Upstream Single Mode (SMF) LC Connector 1310nmTx/1490nmRx Digital Diagnostic Monitoring (DDM) Distances up to 40km (24.8mi)
- **LIFETIME WARRANTY:** Backed by a lifetime warranty on the life of the module itself, not the life of your switch. Our modules won't void your OEM warranty and supported by our Tech Advisors 5/24
- **PROGRAMMED & TESTED FOR COMPATIBILITY:** Compatible with Dell EMC routers and switches. MSA Compliant with DDM that reports the transceiver's status to most SNMP network management tools

---

### Hardware

Warranty	Lifetime
Compatible Brand	Dell EMC
Industry Standards	IEEE 802.3 1000BASE-BX40

---

### Performance

Maximum Data Transfer Rate	1.00 Gbps
Max Transfer Distance	40 km (24.8 mi)
Type	Single Mode
Wavelength	1310nmTx/1490nmRx 1310nmTx/1490nmRx
Fiber Operating Mode	Full-Duplex
DDM	Yes
Compatible Networks	1000 Mbps (1 Gbps)
MTBF	3,713,222 hours

Power Consumption (In Watts) < 1.6W

---

**Physical Characteristics**

Product Length	0.5 in [13.9 mm]
Product Width	2.3 in [58.4 mm]
Product Height	0.5 in [12.6 mm]
Weight of Product	1.1 oz [30 g]

---

**Packaging Information**

Package Length	4.5 in [11.5 cm]
Package Width	3.5 in [90 mm]
Package Height	1.2 in [31 mm]
Shipping (Package) Weight	1.8 oz [50 g]

---

**What's in the Box**

Included in Package	SFP Transceiver
---------------------	-----------------

---

*\*Product appearance and specifications are subject to change without notice.*

