

1 Port Low Profile PCI 10/100 Mbps Ethernet Network Adapter Card

Product ID: ST100SLP



This 1 Port PCI Fast Ethernet Network Adapter Card offers a reliable, cost-effective Ethernet network connection that's ideal for small form factor computers.

Delivering a simple connection to 10/100Mbps (Fast) Ethernet networks, the NIC features auto-negotiation that senses speed and duplex capabilities of connected devices and full duplex support for data transfer rates up to 200Mbps.

A versatile network interface solution, the NIC features a low profile mounting bracket that's suitable for small form factor computers, and is supported by all popular operating systems including Windows, Linux, Mac OS and Novell platforms. Backed by StarTech.com's Lifetime Warranty.

Certifications, Reports and Compatibility

Applications

- Replace a failed Ethernet port in a small form factor computer
- Add networking capabilities to an old system with no Ethernet port
- Add an additional Ethernet port to a desktop or workstation computer for redundancy

Features

- A single 10/100 Mbps compatible RJ45 Ethernet port
- Network Link/Activity and 10/100 Mbps LED indicators

- Fully Compliant with IEEE 802.3, IEEE 802.3u, IEEE 802.3x
- Full and half duplex support
- Crossover Detection & Auto-Correction (Auto MDI/MDI-X)
- Supports optional Boot ROM (Realtek RTL8139D Compatible Boot ROM required)

Hardware

Warranty	Lifetime
Ports	1
Interface	RJ45 (10/100 Ethernet)
Bus Type	PCI / PCI-X (5 / 3.3V)
Card Type	Low Profile (SP bracket incl.)
Industry Standards	IEEE 802.3/802.3u
Chipset ID	Realtek - RTL8100C

Performance

Maximum Data Transfer Rate	200 Mbits/Sec
Compatible Networks	10/100 Mbps
Full Duplex Support	Yes


Connector(s)

Connector Type(s)	PCI / PCI-X (Universal 3.3 & 5V, 32-bit)
External Ports	RJ-45

Software

OS Compatibility	Windows NT, 98SE, 2000, XP, Vista, 7, 8, 8.1, 10 Windows Server 2008 R2, 2012, 2016, 2019 Mac OS 10.0.4, 9.1 / 9.0 Unix, Linux 2.6 to 4.11.x <i>LTS Versions Only</i> NetWare 3.x/4.x
------------------	---

Special Notes / Requirements

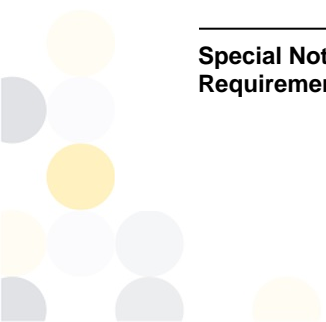

Note IRQ Line and I/O Address Assigned by system

Indicators

LED Indicators 10/100Mbps selection
Network link/activity

Environmental

Operating Temperature 0C to 55C (32F to 131F)
Humidity 10~90% RH Non-condensing

Physical Characteristics

Product Length 4.7 in [12.0 cm]
Product Width 0.8 in [20.0 mm]
Product Height 3.1 in [80.0 mm]
Weight of Product 1.5 oz [42.0 g]

Packaging Information

Package Length 6.7 in [17.1 cm]
Package Width 5.6 in [14.2 cm]
Package Height 1.2 in [30.0 mm]
Shipping (Package) Weight 4.7 oz [132.0 g]

What's in the Box

Included in Package Low Profile 10/100 Mbps Ethernet PCI Card
Full Profile bracket
Driver CD
Instruction Manual

***Product appearance and specifications are subject to change without notice.**

