

DVI Video Extender over Cat 5 UTP

Productcode: ST121UTPDVI



The ST121UTPDVI DVI Video Extender over Cat 5 UTP lets you extend a DVI Digital (DVI-D) video signal over Category 5 (or better) cable at distances of up to 150-feet (45-meters) from the video source to the intended display, without sacrificing video quality.

This cost-effective video extender is simple to use and offers a compact form factor, helping to save valuable work space.

With support for resolutions up to 1600x1200, this DVI extender can be easily integrated using existing Ethernet infrastructure wiring, and offers a completely hardware-based solution with no software or drivers required - perfect for any small scale point-to-point digital signage application that requires high quality DVI video.

Backed by a StarTech.com 2-year warranty and free lifetime technical support.

Certificaties, rapporten en compatibiliteit

Toepassingen

- Place the display in a convenient viewing area, while the system equipment is placed elsewhere in a clean and secure environment
- Ideal for digital signage applications in financial, educational, business and retail/POS sectors

Eigenschappen

- Consists of 1 local unit, and 1 remote unit for an all-in-one solution
- Extends video signal over standard Category 5 UTP cable
- Supports resolutions up to 1600x1200 @ 60Hz
- Supports DVI-D interface

Hardware

Garantiebeleid	2 Years
Poorten	1
Bekabeling	Cat5 UTP of beter
Audio	Nee
Op elkaar aansluitbaar	Nee

Prestaties

Max. afstand	45 m / 150 ft
Maximale digitale resoluties	1600x1200 @ 60Hz
MTBF	180,102 hours

Connector(en)


Connectoren lokale eenheid	DVI-I (29-polig)
	RJ-45
Aansluitingen externe eenheid	DVI-I (29-polig)
	RJ-45

Speciale opmerkingen / vereisten

Notitie	DVI-A (Analog) signal not supported
---------	-------------------------------------

Voeding

Inclusief voedingsadapter	Inclusief 2 wisselstroomadapters
---------------------------	----------------------------------

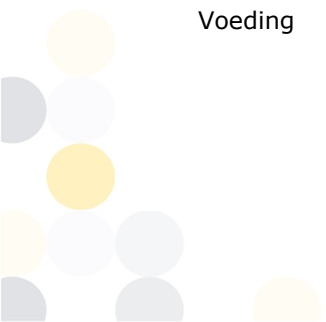

Ingangsspanning	100 - 240 AC
Ingangsstroom	0.2A
Uitgangsspanning	5 DC
Uitgangsstroom	1A
Polariteit pin midden	Positief
Stekkertype	H
Vermogensopname	5

Gebruiksomgeving

Bedrijfstemperatuur	32° to 122° F (0° to 50° C)
Opslagtemperatuur	-4° to 158° F (-20 to 70° C)
Vochtigheid	15 to 90% relative humidity, non-condensing

Fysieke eigenschappen

Kleur	Zwart
Type behuizing	Staal
Lengte product	2.6 in [67.0 mm]
Breedte product	2.0 in [52.0 mm]
Hoogte product	1.5 in [38.0 mm]
Gewicht product	10.1 oz [285.5 g]

Verpakkingsinformatie

Package Length	9.6 in [24.4 cm]
Package Width	2.6 in [67.0 mm]
Package Height	6.1 in [15.5 cm]
Verzendgewicht (verpakt)	22.6 oz [639.0 g]



Wat wordt er
meegeleverd

Meegeleverd

DVI Local Unit Extender

DVI Remote Unit Extender

Power Adapters

Instruction Manual

* Uitvoering en specificaties van het product zijn zonder aankondiging vatbaar voor wijzigingen.

