

## 4 Port VGA and Audio over Cat 5 Video Extender

**Product ID:** ST124UTPEA



The ST124UTPEA VGA Video Extender over Cat 5 with Audio simplifies the implementation of digital signage solutions by allowing a single VGA source and corresponding audio to be broadcast to multiple displays at up to 300m (950ft) away over standard Cat 5 or better UTP cabling.

Consisting of the transmitter unit only, this product requires a single receiver unit per remote display that you are connecting. The VGA extender offers the option of using our STUTPEALR receiver unit, or the STUTPRXWLA wall-plate receiver.

For even more versatility, you also have the option to expand the amount of remote displays in your setup by adding the STUTPEA4X VGA & Audio over Cat 5 Line Splitter to your setup multiplying the number of potential displays by four - allowing your VGA and accompanying audio signal to be broadcast to up to a total 16 displays.

Backed by a StarTech.com 2-year warranty and free lifetime technical support.

## Certifications, Reports and Compatibility

### Applications

- Use digital signage to catch the attention of your audience and deliver up to date content the way you want it to be seen and heard
- Place the display in a convenient viewing area, while the system equipment is placed elsewhere in a clean and secure environment
- Ideal for digital signage applications in financial, educational, and business sectors
- Extend your display across harsh environment industrial sites

- Perfect for video conferencing solutions in boardrooms and office settings
- Optimize placement of your demo stations at trade-shows and in auditoriums

## Features

- Deliver VGA video and audio to monitors located up to 300m / 950ft away at 1280x1024 / 720p
- Extend using standard Cat 5 or better cabling
- Supports maximum resolutions of up to 1920x1080 / 1080p @ 75m / 250ft
- Can be used with four port line splitters (STUTPEA4X) to run a maximum of 16 displays
- Pure hardware design, no software or drivers required

---

### Hardware

Warranty	2 Years
Ports	4
Cabling	Cat 5 UTP or better
Audio	Yes
Daisy-Chain	Yes

---

### Performance

Max Distance	300 m / 950 ft
Supported Resolutions	1920x1200 @ 75m(250ft) 1440x900 @ 150m(500ft) 1024x768 @ 300m(950ft)
Audio Specifications	3.5mm Stereo audio supported

---


### Connector(s)

Local Unit Connectors	RJ-45  VGA (15 pin, High Density D-Sub)
-----------------------	-----------------------------------------------

---

### Special Notes / Requirements

System and Cable Requirements	One <a class="FeatureNavLink" href="http://www.startech.com/item/STUTPEALR">STUTPEALR</a> standalone, or <a class="featurenavlink" href="http://www.startech.com/item/STUTPRXWLA">STUTPRX</a>
-------------------------------	-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------

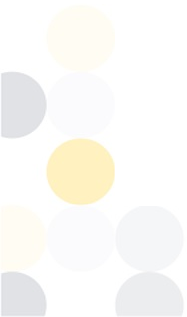

WLA wall-plate receiver unit per display that you are connecting

---

**Power**

Power Source	AC Adapter Included
Output Voltage	12V DC
Output Current	0.6A
Power Consumption (In Watts)	7.2

---

**Environmental**

Operating Temperature	0C to 50C (32F to 122F)
Storage Temperature	-20C to 70C (-4F to 158F)
Humidity	5~90% RH

---

**Physical Characteristics**

Color	Black
Material	Aluminum
Product Length	8.7 in [22.0 cm]
Product Width	4.7 in [11.9 cm]
Product Height	1.6 in [41.0 mm]
Weight of Product	23.3 oz [660.0 g]

---

**Packaging Information**

Package Length	12.2 in [31.0 cm]
Package Width	2.8 in [70.0 mm]
Package Height	10.0 in [25.5 cm]
Shipping (Package) Weight	4.0 lb [1.8 kg]

---

**What's in the Box**

Included in Package	4 Port VGA and Audio Over Cat5 Transmitter
	Mounting Brackets



VGA Cable M/M (3 ft)

3.5 MM Audio Cable M/M (3 ft)

1 Bag (Screws)

Universal Power Adapter (NA/UK/EU)

Instruction Manual

---

***\*Product appearance and specifications are subject to change without notice.***

