

4 Port Black SuperSpeed USB 3.0 Hub

Product ID: ST4300USB3GB




The ST4300USB3GB 4-Port SuperSpeed USB 3.0 Hub allows you to add 4 additional USB 3.0 ports from a single USB 3.0 connection to the host computer system.

Backward compatible with USB 2.0 and USB 1.x standards, this USB 3.0 hub still supports older USB devices and can also be used as a hub on older systems that do not have USB 3.0 ports.

With the capability to mix and match USB 3.0/2.0/1.x devices and be used with or without the included external power adapter, this hub offers the best of versatility and portability.

Backed by a StarTech.com 2-year warranty and free lifetime technical support.

Certifications, Reports and Compatibility

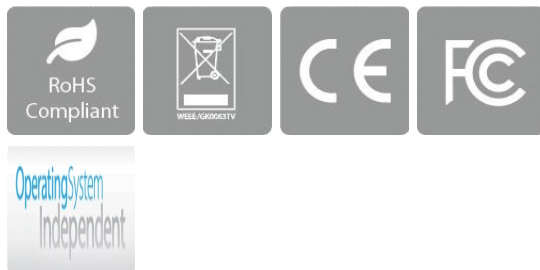

Applications

- Expand your USB 3.0 capabilities with additional ports
- Make hard to access USB ports more accessible by being able to position the hub anywhere the cable will reach

- Extend the range of a USB device by having the hub act as a mid-point repeater

Features

- Four USB type 'A' ports that can each be accessed simultaneously
- SuperSpeed USB 3.0 compliant, with data transfer rates up to 5 Gbps
- Backward compatible with USB 2.0 and USB 1.0/1.1 devices
- Supports USB 3.0/2.0/1.x devices simultaneously at full bandwidth
- Provides up to 900mA on any port up to a maximum of 2000mA total
- Compact, desktop-style form factor
- Plug-and-Play and hot-swap compatible

Hardware

| | |
|-----------------------|-----------------------|
| Warranty | 2 Years |
| USB-C Device Port(s) | No |
| USB-C Host Connection | No |
| Fast-Charge Port(s) | No |
| Ports | 4 |
| Interface | USB 3.2 Gen 1 (5Gbps) |
| Bus Type | USB 3.2 Gen 1 (5Gbps) |
| | USB 3.2 Gen 1 (5Gbps) |
| Chipset ID | VIA/VLI - VL811+ |

Performance

| | |
|----------------------------|--------|
| Total USB Power Output | 10W |
| Maximum Data Transfer Rate | 5 Gbps |

Connector(s)

| | |
|----------------|--|
| External Ports | 4 - USB Type-A (9 pin, 5 Gbps) |
| | 1 - USB 3.2 Type-B (9 pin, Gen 1, 5Gbps) |

Software

| | |
|------------------|--|
| OS Compatibility | OS Independent; No additional drivers or software required |
|------------------|--|

Special Notes / Requirements

| | |
|-------------------------------|--|
| System and Cable Requirements | USB 3.0 or 2.0 or 1.x compliant host controller with available port. |
|-------------------------------|--|

Indicators

| | |
|----------------|------------------|
| LED Indicators | 1 - Power (Blue) |
|----------------|------------------|

Power

| | |
|------------------------------|---------------------|
| Power Source | AC Adapter Included |
| Input Voltage | 100 - 240 AC |
| Output Voltage | 5 DC |
| Output Current | 2A |
| Center Tip Polarity | Positive |
| Plug Type | M |
| Power Consumption (In Watts) | 10 |

Environmental

| | |
|-----------------------|---------------------------|
| Operating Temperature | 0C to 50C (32F to 122F) |
| Storage Temperature | -20C to 60C (-4F to 140F) |
| Humidity | 5~85% RH |

Physical Characteristics

| | |
|----------------|-----------------|
| Color | Black |
| Form Factor | Desktop |
| Material | Plastic |
| Product Length | 3.7 in [95 mm] |
| Product Width | 2.7 in [6.8 cm] |
| Product Height | 0.9 in [2.3 cm] |

Weight of Product 1.9 oz [55 g]

Packaging Information

Package Quantity 1

Package Length 8.3 in [21 cm]

Package Width 5.9 in [15 cm]

Package Height 3.1 in [80 mm]

Shipping (Package) Weight 1.0 lb [0.4 kg]

What's in the Box

Included in Package

- 1 - USB 3.0 Hub
- 1 - 0.91 m [3 ft] USB 3.0 cable
- 1 - Power Adapter
- 1 - Instruction Manual

**Product appearance and specifications are subject to change without notice.*