

16 Port 1U Rackmount USB PS/2 KVM Switch with OSD - TAA

Produkt-ID: SV1631DUSB



The SV1631DUSBGB 16 Port 1U Rack Mount USB PS/2 KVM Switch with OSD offers a dependable computer management tool that allows you to control up to 16 USB or PS/2 connected computers from a single keyboard, mouse and monitor.

The KVM switch offers maximum control, allowing you to switch computers using hotkey commands or front panel push-buttons, and offers the added convenience of an On Screen Display to quickly access configuration options.

A suitable addition to server room operations, the 16 port switch can be rack-mounted into 1U of cabinet space, and can be cascaded with multiple KVM switches to deliver control of up to 136 computers from this single switch.

This high quality USB PS/2 KVM Switch is TAA compliant and backed by a StarTech.com 3-year warranty with free lifetime technical support.

The SV1631DUSB only works with specific 2-in-1 VGA and USB cables (sold separately), a list of StarTech.com approved cables are below:


6 ft Ultra Thin USB VGA 2-in-1 KVM Cable

6 ft Ultra Thin USB VGA 2-in-1 KVM Cable

10 ft Ultra Thin USB VGA 2-in-1 KVM Cable

15 ft Ultra Thin USB VGA 2-in-1 KVM Cable

Zertifikate Berichte und Kompatibilität

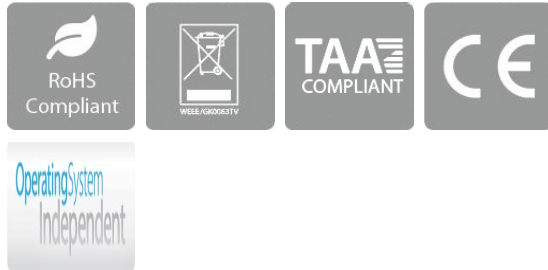

Anwendungen

- Add single console administration to your Co-location/ISP facility saving you time and money
- Create a scalable, streamlined access solution in your Datacenter or Server Farm
- Perfect for manufacturing line computer control, simplifying access to multiple systems
- Great for PC test/burn-in computer control saving the desk space required for multiple monitors, keyboards and mice

Merkmale

- Connect USB and PS/2 based computer systems
- OS independent – No software or drivers required
- Auto-scan function cycles through computers sequentially
- Cascade configuration expands system capability
- Front panel push-buttons and Hot-key functions allow for easy switching
- On Screen Display (OSD) supports naming connected computers
- USB & PS2 console interfaces for keyboard and mouse
- OSD security option allows selected PCs to be password protected from unauthorized use

Hardware

Garantiebestimmungen 3 Years

Audio Nein

KVM-Ports 16

PC-Schnittstelle USB und PS/2

PC-Videotyp	VGA
Mehrfach-Monitor	1
Einbaufähig	Ja
Mit Kabeln	Nein
Reihenschaltung	Ja

Leistung

OSD- & Schnell Tastenunterstützung	Nein
DVI-Unterstützung	Nein
IP-Steuerung	Nein
Hot-Key Selection	Ja
Max. Analogauflösungen	1920 x 1440 @60hz
Max. Anzahl von Benutzern	1
Max. kaskadierte Computer	136
Portauswahlunterstützung	Drucktaste und Schnell Tasten
MTBF	158000 Stunden

Software

Betriebssystemkompatibilität	OS independent; No software or drivers required
------------------------------	---

Strom

Stromversorgung	Mit Netzadapter
Eingangsspannung	100 - 240 AC
Eingangsstrom	0.2A
Ausgangsspannung	9V DC

Ausgangsstrom	0.6A
Polarität der Mittelspitze	Positiv
Steckertyp	M
Stromverbrauch	5.4

Umgebungsbedingungen

Betriebstemperatur	5°C to 40°C (41°F to 104°F)
Lagertemperatur	-20°C to 60°C (-4°F to 140°F)
Feuchtigkeit	0~80% RH

Physische Eigenschaften

Farbe	Schwarz
Gehäusotyp	Stahl
Produktlänge	17.2 in [43.8 cm]
Produktbreite	7.1 in [18 cm]
Produkthöhe	1.8 in [4.5 cm]
Produktgewicht	6.8 lb [3.1 kg]

Verpackungsinformationen

Paketmenge	1
Paketlänge	18.7 in [47.6 cm]
Paketbreite	9.6 in [24.4 cm]
Pakethöhe	3.7 in [9.5 cm]
Versandgewicht (Verpackung)	6.9 lb [3.1 kg]

Verpackungsinhalt

Im Paket enthalten	1 - 16 Port KVM Switch
--------------------	------------------------

2 - Mounting Brackets

1 - PS/2 keyboard and mouse Y cable

1 - Universal-Netzadapter (NA/UK/EU)

4 - Fußmatten

1 - User Manual

Garantieinformatio
nen

Warranty

3 Jahre

* Größe, Aussehen und Spezifikationen sind Änderungen ohne vorherige Ankündigung vorbehalten.