

2 Port USB HDMI Cable KVM Switch with Audio and Remote Switch – USB Powered

Produkt ID: SV211HDUA



The SV211HDUA 2-Port HDMI® Cable KVM Switch with Audio and Remote Switching Control lets you control two HDMI, USB equipped PCs with a single monitor, keyboard, mouse and audio peripheral set.

To help organize your desk without sacrificing work space, this compact HDMI USB KVM features integrated cables that can be connected directly to your system, while leaving a minimal footprint. The switch features a remote push-button on a 1.5 meter (5ft) integrated cable that can be placed in an easily accessible location, as well as keyboard hot-keys, and PC or Mac® compatible software for switching between systems. To eliminate the need for a bulky external power adapter and wall outlet, the HDMI KVM switch is USB-powered.

This KVM with HDMI video capability offers support for 1080p HD resolutions (up to 1920x1200) for the ability to drive a large HDMI display for applications that require high graphical output.

Backed by a StarTech.com 2-year warranty and free lifetime technical support.

Certifikat, rapporter och kompatibilitet

Användning

- Great for PC test/burn-in computer control, saving the desk space required for two monitors, keyboards and mice
- Perfect for sharing computers and attached peripherals in the home or home office
- Dual system control for single user workstations increasing user productivity in the office

Funktioner

- Space-saving design, minimal footprint
- USB Powered - No external power adapter required
- Remote switch on 1.5m (5ft.) cable
- Supports HD resolutions (1080p - 1920x1200)
- Switching software supports PC and Mac® platforms
- Supports hot-plugging
- Switch PCs via push-button, hot-keys or switching software
- Integrated KVM cables and remote switch
- Independent audio/mic switching for uninterrupted audio
- Analog (3.5mm) and HDMI audio supported

Hårdvara

Garantipolicy	2 Years
Audio	Ja
KVM-portar	2
PC-gränssnitt	USB
PC-videotyp	HDMI
Flera skärmar	1
Hyllmonterbar	Nej
Medföljande kablar	Ja
Industristandarder	HDCP
Kedjekoppling	Nej

Prestanda

Skärmvisning (OSD) & Nej



stöd för
snabbtangenter

IP-kontroll	Nej
Hot-Key Selection	Ja
Audio-specifikationer	3.5mm and HDMI audio supported
Stöd för portval	Tryckknapp, genvägskommandon och mjukvara

Kontakt(er)

Konsolgränssnitt	HDMI (19-stifts)
	3.5 mm minijack (3-polig)
	USB Type-A (4-stifts) USB 2.0
Värdkontakter	USB Type-A (4-stifts) USB 2.0
	HDMI (19-stifts)
	3.5 mm minijack (3-polig)

Mjukvara

OS-kompatibilitet	Windows® 2000, XP, Vista, 7, 8, 8.1, 10
	Windows Server® 2003, 2008 R2, 2012, 2016, 2019
	Mac OS 10.6 till 10.9

Särskilda
anmärkningar/
krav

Obs.	OS Compatibility refers to KVM software only - the KVM itself can be used without software on any platform
------	--

Indikatorer


LED-indikatorer	PC Selection indicator
-----------------	------------------------

Ström

Power Source	Strömförsörjd via USB
--------------	-----------------------

Miljö

Drifttemperatur	0°C to 40°C (32°F to 104°F)
-----------------	-----------------------------

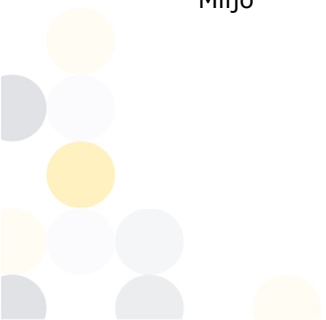

Förvaringstemperatur -20°C to 60°C (4°F to 140°F)

Luftfuktighet 0~90% RH Non-Condensing

Utseende

Färg	Svart
Kabinettyp	Av plast
Kabellängd	33.5 in [85 cm]
Produktlängd	3.5 in [88 mm]
Produktbredd	2.6 in [66 mm]
Produkt höjd	0.9 in [23 mm]
Produktvikt	12.4 oz [350 g]

Förpackning

Package Length	9.8 in [25 cm]
Package Width	6.3 in [16.1 cm]
Package Height	2.4 in [62 mm]
Fraktvikt (förpackning)	16.4 oz [464 g]

Vad det är i lådan

Ingår i paketet	KVM Switch
	Software CD
	Instruction Manual

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.

