

2 Port Black PS/2 KVM Switch Kit with Cables

Produkt ID: SV211K




This 2 Port KVM Switch Kit lets you control two computers using a single keyboard, mouse and VGA monitor and offers both hotkey and top panel push-button operation for simple switching between connected computers.

Designed to integrate seamlessly into any environment, the KVM switch offers a small footprint design (roughly the size of a deck of playing cards) and draws power from the connected computers, so it doesn't require an external power supply.

A suitable solution for virtually any application, the KVM switch supports video resolutions of up to 2048 x 1536 and includes 3-in-1 (PS/2 and Video) cables to provide a complete, out-of-the-box KVM solution.

Delivering dependable and convenient control of multiple computers from a single peripheral station, this high quality KVM switch is backed by StarTech.com's 2-year warranty and free lifetime technical support.

Certifikat, rapporter och kompatibilitet

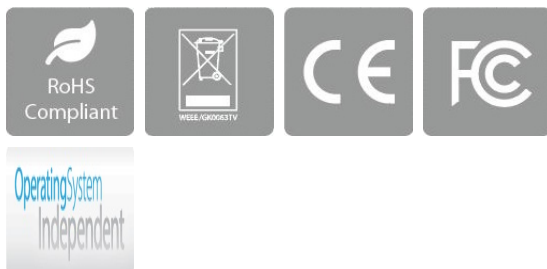

Användning

- Perfect for integrating two different enterprise computer systems.
- Useful for call centers, help desks, education environments, home gamers and PC enthusiasts.

Funktioner

- All cables come out of the rear of the switch unlike competitor 3-sided "octopus" designs.
- Hot plug - computers can be added without resetting switches or other connected computers.
- Includes two (2) 6 ft. cables.

Hårdvara

Garantipolicy	2 Years
Audio	Nej
KVM-portar	2
PC-gränssnitt	PS/2
PC-videotyp	VGA
Flera skärmar	1
Hyllmonterbar	Nej
Medföljande kablar	Ja
Kedjekoppling	Nej

Prestanda

DVI-stöd	Nej
IP-kontroll	Nej
Hot-Key Selection	Nej
Maximal kabellängd	6.0 ft [1.8 m]
Maximal analog upplösning	1920 x 1440
Auto Scan	3, 8, 15 & 30 sekunder

	Maximalt antal användare	1
Kontakt(er)	Konsolgränssnitt	2 - PS/2 (6-stifts, Mini-DIN)
		1 - VGA (15-stifts, High Density D-Sub)
	Värdkontakter	2 - VGA (15-stifts, High Density D-Sub)
Mjukvara	OS-kompatibilitet	OS independent; No software or drivers required
Särskilda anmärkningar/krav	Obs.	Optional Power Adapter requires 9V DC, 600 mA, center positive
Ström	Strömkälla	Medföljer ej (behövs ej vid vanlig användning)
Utseende	Färg	Svart
	Kabinetttyp	Av plast
	Produktlängd	6.3 in [16 cm]
	Produktbredd	2.8 in [7 cm]
	Produkthöjd	0.8 in [2.1 cm]
Förpackning	Paketets längd	8.6 in [21.8 cm]
	Paketets bredd	3.9 in [10 cm]
	Paketets höjd	3.8 in [96 mm]
	Fraktvikt (förpackning)	1.6 lb [0.7 kg]
Vad det är i lådan	Ingår i paketet	1 - 2 Port PS/2 KVM Switch Kit with Cables

2 - Cables

4 - Rubber Feet

1 - Instruction Manual

Warranty
Information

Warranty

2 År

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.