

2 Port Professional USB DisplayPort KVM Switch with Hotkey Control

Produkt ID: SV231DPU



This 2-Port USB DisplayPort KVM Switch combines the next generation of digital display interface standards with seamless KVM control of connected PC or Mac computers.

Delivering ideal multi-computer control for demanding high-resolution multimedia applications, or computer environments requiring true high definition capability, the robust KVM switch supports DisplayPort connections with a native resolution of 2560 x 1600 (@60 Hz, 30 bpp), as well as 7.1 HD digital audio (when connected to supporting displays and sources).


Suitable for applications that utilize high quality static imaging, such as medical/health care applications (MRI, X-ray diagnostics etc.), the KVM switch supports a maximum resolution of 3840 x 2400 at a reduced refresh rate.

Adding cost-effective performance to cutting-edge multimedia capability, this versatile KVM switch features three Plug-and-Play USB console ports, including two dedicated peripheral (mouse and keyboard) ports and one USB 2.0 hub port - enabling users to share a USB mouse and keyboard, and one USB 2.0 peripheral between the two connected Mac or PC computers.

A simple, yet comprehensive control solution, the 2-port KVM switch features both front-panel push-button and convenient hotkey switching and offers a small form factor design with connection ports situated on the rear panel, allowing you to eliminate workspace disruptions.

The SV231DPU DisplayPort KVM switch is backed by our 3-year warranty and free lifetime technical support, guaranteeing dependable, long-lasting performance.

Certifikat, rapporter och kompatibilitet

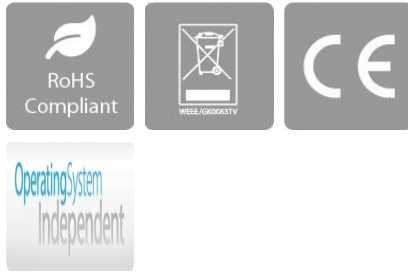

Användning

- Ideal for multimedia design, post-production and video editing using Mac or PC computers
- Provide centralized control for multiple high-res Digital Signage server control
- Useful in high resolution medical imaging and Health care displays, such as MRI and Xray display
- Good for manufacturing line computer control, simplifying access to multiple systems
- Great for PC test/burn-in computer control saving the desk space required for two monitors, keyboards and mice
- Dual system control for single user workstations increasing user productivity in the office
- Consolidate your Satellite Topography systems into a single console

Funktioner

- StarTech.com is the first to introduce a DisplayPort KVM into the Market
- OS independent - No driver or software installation required
- Native resolution: 2560 x 1600 @ 60Hz, beyond 1080p
- Hot-key and push-button switching
- Supports a maximum resolution of 3840 x 2400 at lower refresh rates
- Supports native DisplayPort computer connections - no adapter required
- Compatible with Mini-DisplayPort adapters
- 7.1 Channel High Definition Audio support
- USB 2.0 peripheral sharing
- Full plug-and-play support with USB keyboards, mice, and connected peripherals
- Supports hot-plug or disconnect and link status-failure detection

- VESA and CEA compliant
- User-defined scan time intervals
- Supports DDC2B for monitor detection
- Direct Drive support

Hårdvara

Garantipolicy	3 Years
Audio	Ja
KVM-portar	2
PC-gränssnitt	USB
PC-videotyp	DisplayPort
Flera skärmar	1
Hyllmonterbar	Nej
Medföljande kablar	Nej
Kedjekoppling	Nej

Prestanda

Skärmvisning (OSD) & stöd för snabbtangenter	Nej
DVI-stöd	Ja - Dual Link
IP-kontroll	Nej
Hot-Key Selection	Ja
Maximal digital upplösning	2560 x 1600 @ 60Hz
Stöd för widescreen	Ja
Maximalt antal användare	1

	Stöd för portval	Tryckknapp och genvägskommandon
Kontakt(er)		
	Konsolgränssnitt	1 - DisplayPort (20-stifts) 3 - USB 2.0 Type-A (4 stift, 480 Mbps)
	Värdkontakter	2 - DisplayPort (20-stifts) 2 - USB B (4-stifts)
Mjukvara	OS-kompatibilitet	OS independent; No software or drivers required
Indikatorer		
	LED-indikatorer	2 - Green - Online indicator (One LED per port) 2 - Red - Select indicator (One LED per port)
Ström	Strömkälla	AC-adapter medföljer
	Inspänning	110V-240V AC
	Inström	0.4A
	Utpänning	5 DC
	Utström	2A
	Polaritet på mittpol	Positiv
	Kontakttyp	N
Utseende	Färg	Svart
	Kabinettyp	Stål
	Produktbredd	5.0 in [12.6 cm]
	Produkthöjd	1.6 in [4 cm]
	Produktdjup	2.6 in [65 mm]
	Produktvikt	14.7 oz [417.3 g]

Förpackning

Paketets längd	9.4 in [23.9 cm]
Paketets bredd	4.0 in [10.2 cm]
Paketets höjd	8.5 in [21.5 cm]
Fraktvikt (förpackning)	3.0 lb [1.3 kg]

Vad det är i lådan

Ingår i paketet	1 - 2 port DisplayPort KVM
	1 - Rubber Feet
	1 - Universal Power Adapter (US/UK/EU)
	1 - Manual

Warranty
Information

Warranty	3 År
----------	------

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.