

2 Port USB HDMI KVM Switch with Audio and USB 2.0 Hub

Produkt ID: SV231HDMIUA



The SV231HDMIUA 2-port USB HDMI® KVM Switch lets you control two USB-enabled multimedia computers or devices with HDMI video interfaces, using a single peripheral set/console (USB keyboard, mouse, monitor, speakers and microphone).

A highly versatile KVM solution, the USB HDMI KVM Switch features an integrated 2-port USB 2.0 hub that lets selected computers access shared high speed USB devices, eliminating the cost of duplicate USB peripheral purchases.

Ensuring high quality video capability, the HDMI KVM switch supports HD resolutions of up to 1920 x 1200. Offering genuine digital signal transmission over the cable, this switch can be used to share one HD panel between multiple HDMI sources such as Blu-Ray players, Video Game consoles and HD media centers.

The switch also supports audio and microphone switching functions and allows you to select connected computers, USB device hub ports and audio/mic channels either simultaneously or independently using either front-panel push-buttons or keyboard hotkeys.

This product is TAA compliant and backed by a Startech.com 3-year warranty with free lifetime technical support.

Certifikat, rapporter och kompatibilitet

Användning

- Use in the Office to connect two multimedia PCs to a single console connection increasing productivity

- Students can use a single monitor and connect their gaming console along side their PC or laptop
- Allows multimedia PCs to share peripherals and a single high definition television
- Ideal for sharing two newer HDMI® multimedia PCs with an HDMI monitor

Funktioner

- Integrated USB 2.0 hub - Share USB peripherals between PCs
- Supports High Resolutions Digital video up to UXGA (1600x1200), WUXGA (1920x1200), and 1080p (1920x1080)
- Independent Audio switching
- Supports push button and hotkey PC Switching
- Manual video adjustments via rear function button
- Supports Plug&Play operation
- Audible tone to indicate PC switching
- No software drivers required; OS independent
- User-defined scan time intervals
- Supports both HDMI® audio and 3.5mm analog audio

Hårdvara

Garantipolicy	3 Years
Audio	Ja
KVM-portar	2
PC-gränssnitt	USB
PC-videotyp	HDMI
Flera skärmar	1
Hyllmonterbar	Nej
Medföljande kablar	Nej

Kedjekoppling Nej

Prestanda

Skärmvisning (OSD) & stöd för snabbtangenter Nej

IP-kontroll Nej

Hot-Key Selection Ja

Maximal digital upplösning 1920 x 1200

Stöd för widescreen Ja

Maximalt antal användare 1

Stöd för portval Tryckknapp och genvägskommandon

Medeltid mellan fel (MTBF) 126813 hours

Kontakt(er)

Konsolgränssnitt HDMI (19-stifts)
USB Type-A (4-stifts) USB 2.0
3.5 mm minijack (3-polig)

Värdkontakter HDMI (19-stifts)
USB B (4-stifts)
3.5 mm minijack (3-polig)

Mjukvara


OS-kompatibilitet OS independent; No software or drivers required

Indikatorer

LED-indikatorer Online/Active (Green - Connected PC is online, Red - PC is selected)

Ström

Power Source AC-adapter medföljer

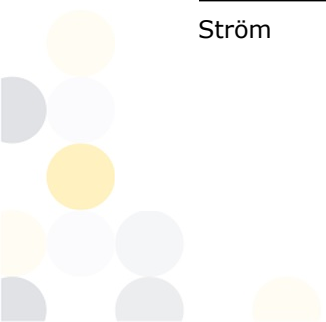

Inspänning	100 - 240 AC
Inström	0.8A
Utspänning	12V DC
Utström	1.5A
Polaritet på mittpol	Positiv
Kontakttyp	M
Strömförbrukning	18

Miljö

Drifttemperatur	0°C to 40°C (32°F to 104°F)
Förvaringstemperatur	-20°C to 60°C (-4°F to 140°F)
Luftfuktighet	0~80% RH

Utseende

Färg	Svart
Kabinettyp	Stål
Produktbredd	4.9 in [12.5 cm]
Produkt höjd	1.6 in [40 mm]
Produkt djup	2.8 in [70 mm]
Produktvikt	22.4 oz [634 g]

Förpackning

Package Length	9.8 in [25 cm]
Package Width	7.4 in [18.8 cm]
Package Height	3.9 in [100 mm]
Fraktvikt (förpackning)	2.4 lb [1.1 kg]

Vad det är i lådan

Ingår i paketet	2 Port HDMI KVM
-----------------	-----------------



Power Adapter

User Manual

Package of Rubber feet

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.

