

## 4 Port SuperSpeed USB 3.0 DisplayPort KVM Switch with Audio and Cables

**Product ID:** SV431DPU3A




The SV431DPU3A 4-Port USB 3.0 DisplayPort KVM Switch lets you control 4 DisplayPort, USB 3.0-equipped PCs with a single monitor, keyboard, mouse and audio peripheral set. For added convenience, the included KVM cables provide a ready-to-use KVM solution.

This USB 3.0 KVM Switch offers an integrated 2-port hub that supports USB 3.0 data rates up to 5 Gbps, and is backward compatible with USB 2.0 and 1.1/1.0 devices, ensuring flawless performance for your USB peripherals.

Offering support for high resolutions (up to 2560x1600), this 4-port DisplayPort KVM switch has the ability to drive large DisplayPort displays with ease, making it ideal for graphical applications that require high-res video output.

Backed by a StarTech.com 2-year warranty and free lifetime technical support.

### Certifications, Reports and Compatibility

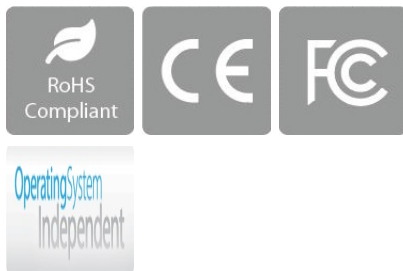

### Applications

- Control four DisplayPort USB computers with a single set of console peripherals (Keyboard, Mouse, and Monitor)
- Ideal for financial/banking industries, graphic designers, multi-media applications and industries using CAD/CAM

applications

- Integrated USB 3.0 hub and Mic/Audio allows the user to have full multimedia control of two computers and share USB peripherals in a home or office

## Features

- Integrated USB 3.0 (5 Gbps) hub
- Hot-key and front-panel push buttons for easy computer selection
- Video, audio and USB cables included
- Supports resolutions up to 2560x1600
- No software or drivers required
- USB keyboard and mouse console connections
- Stereo audio and microphone support

---

### Hardware

Warranty	2 Years
Audio	Yes
KVM Ports	4
PC Interface	USB 3.2 Gen 1 (5Gbps)
PC Video Type	DisplayPort
Number of Monitors Supported	1
Rack-Mountable	No
Cables Included	Yes
Daisy-Chain	No

---

### Performance

IP Control	No
Hot-Key Selection	Yes
Maximum Cable Length	32.8 ft [10 m]
Maximum Analog	2560 x 1600

Resolutions	
Audio Specifications	2-Channel Stereo supported
Port Selection Support	Push Button and Hotkeys
MTBF	117,726 Hours

#### Connector(s)

Console Interface(s)	1 - DisplayPort (20 pin)
	2 - 3.5 mm Mini-Jack (3 Position)
	2 - USB 2.0 Type-A (4 pin, 480Mbps)
Host Connectors	4 - USB 3.2 Type-B (9 pin, Gen 1, 5Gbps)
	8 - 3.5 mm Mini-Jack (3 Position)
	4 - DisplayPort (20 pin)
Other Interface(s)	2 - USB Type-A (9 pin, 5 Gbps)

#### Software

OS Compatibility	OS independent; No software or drivers required
------------------	---

#### Indicators

LED Indicators	4 - PC Selection Indicator
	4 - Hub selection indicator

#### Power

Power Source	AC Adapter Included
Input Voltage	100 - 240 AC
Input Current	0.5 A
Output Voltage	9V DC
Output Current	2 A
Center Tip Polarity	Positive
Plug Type	M

#### Environmental

Operating Temperature	0C to 40C (32F to 104F)
-----------------------	-------------------------

Storage Temperature	-20C to 60C (4F to 140F)
Humidity	0~90% RH Non-Condensing

---

#### Physical Characteristics

Color	Black
Material	Steel
Product Length	10.0 in [25.5 cm]
Product Width	4.0 in [10.2 cm]
Product Height	1.8 in [4.5 cm]
Weight of Product	32.5 oz [920 g]

---

#### Packaging Information

Package Quantity	1
Package Length	10.6 in [26.8 cm]
Package Width	7.5 in [19.2 cm]
Package Height	6.3 in [16 cm]
Shipping (Package) Weight	5.8 lb [2.6 kg]

---

#### What's in the Box

Included in Package	1 - 4 Port USB 3.0 KVM Switch
	4 - DisplayPort M/M Cables
	4 - USB 3.0 A-B Cables
	4 - 3.5mm Audio/Mic Cables
	1 - Universal Power Adapter (NA/UK/EU)
	1 - Instruction Manual

---

***\*Product appearance and specifications are subject to change without notice.***