

4 Port Dual DVI USB KVM Switch with Audio


Product ID: SV431DVIDGB



This 4 Port Dual DVI USB KVM Switch allows four PCs, each with dual DVI displays, to share two monitors, one microphone (and set of speakers), one keyboard and one mouse as well as two other USB peripherals.

An ideal solution for graphic designers, CAD/CAM designers or educational and financial institutions, the Dual View KVM Switch allows you to instantly switch back and forth between PCs at the touch of a button while maintaining professional level video quality on both DVI monitors, in turn saving money by eliminating redundant peripheral purchases.

Certifications, Reports and Compatibility

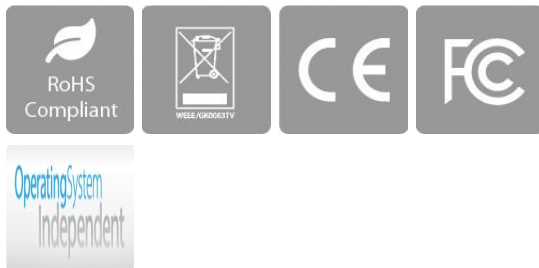

Applications

- Can be used with computers that have a Dual Head DVI video card
- Control up to four multimedia computers with one keyboard, Mouse with dual display
- Ideal for financial/banking industries, graphic designers, multi-media applications and industries using CAD/CAM applications

- Integrated USB 2.0 hub and Mic/Audio switching allows the user to have full multimedia control of two computers and share USB peripherals

Features

- Direct channel selection and operation using front-panel push button and keyboard hotkeys
- HDCP compliant
- Solid metal casing for the maximum durability
- Status LED display for easy port status monitoring
- USB style keyboard and mouse control, plus two other USB peripherals
- User-configurable simultaneous/independent switching of audio and USB hub ports or PC ports

Hardware

Warranty	2 Years
Audio	Yes
KVM Ports	4
PC Interface	USB
PC Video Type	DVI
Number of Monitors Supported	Yes
Rack-Mountable	No
Cables Included	No
Daisy-Chain	No

Performance

DVI Support	Yes - Single Link
IP Control	No
Hot-Key Selection	Yes
Maximum Analog Resolutions	2048x1536
Maximum Digital Resolutions	1920x1200

Maximum Number of Users	1
Port Selection Support	Push Button and Hotkeys

Connector(s)

Console Interface(s)	2 - 3.5 mm Mini-Jack (3 Position)
	2 - DVI-I (29 pin)
	2 - USB 2.0 Type-A (4 pin, 480Mbps)
Host Connectors	8 - 3.5 mm Mini-Jack (3 Position)
	8 - DVI-I (29 pin)
	4 - USB B (4 pin)
Other Interface(s)	2 - USB 2.0 Type-A (4 pin, 480Mbps)

Software

OS Compatibility	OS independent; No software or drivers required
------------------	---

Power

Power Source	AC Adapter Included
Output Voltage	9V DC
Output Current	1.7A
Center Tip Polarity	Positive

Physical Characteristics

Color	Black
Material	Steel
Product Width	10.0 in [25.3 cm]
Product Height	2.6 in [6.6 cm]
Product Depth	3.9 in [100 mm]
Weight of Product	2.5 lb [1.2 kg]

Packaging

Information

Package Length	10.6 in [27 cm]
Package Width	6.3 in [16 cm]
Package Height	7.5 in [19 cm]
Shipping (Package) Weight	3.5 lb [1.6 kg]

What's in the Box

Included in Package	1 - four port KVM
	1 - Power Adapter
	1 - Manual

Warranty Information

Warranty	2 Years
----------	---------

****Product appearance and specifications are subject to change without notice.***