

## 3.5in Black USB 2.0 to IDE SATA External Hard Drive Enclosure


**Product ID:** UNI3510U2



This hybrid, 3.5in USB 2.0 to IDE/SATA Hard Drive Enclosure lets you turn almost any 3.5in hard drive into a portable storage device! Compatible with both IDE (66/100/133) or SATA (SATA, SATA II, SATA III) hard drives, the enclosure offers a cost-effective and convenient choice for a variety of uses including data backups, digital image storage, multimedia storage, or simply putting an "outdated" drive to good use. Large capacity drives (tested with up to 4TB) can be used to greatly enhance your computer's storage/backup capabilities.

The UNI3510U2 IDE/SATA hard drive enclosure is designed and built to provide extreme durability and stability, while remaining an attractive addition to any environment with a stylish aluminum casing and fixed luminescent base that glows an eye-catching blue while the enclosure is powered.

## Certifications, Reports and Compatibility

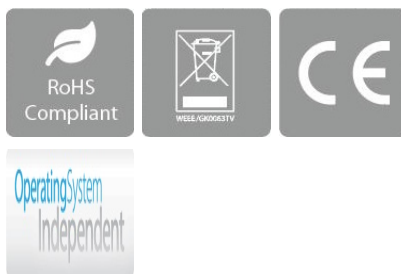

## Applications

- Turn an unused IDE (PATA) or SATA hard drive into additional external storage
- Technicians who work with and need to access a variety of different drives
- Create a fast, portable external storage solution for desktops, laptops or netbooks

- Add-on storage to any USB enabled computer system
- Backup data to an external storage device for archiving or freeing up space

## Features

- Accepts either SATA or IDE (PATA) drives
- High Speed USB 2.0 compliant host interface, with support for transfer rates up to 480 Mbps
- Compatible with SATA 1.5/3.0/6.0Gbps or IDE 66/100/133 Mbps hard drives
- Supports 3.5" form factor hard drives
- Plug-and-Play and Hot-Swap compatible
- Compact, light-weight design

---

### Hardware

Warranty	2 Years
Fan(s)	No
Interface	USB 2.0
Number of Drives	1
Drive Size	3.5in
Compatible Drive Types	SATA & IDE
Drive Installation	Fixed
Number of internal 3.5 inch bays	1

---

### Performance

Maximum Data Transfer Rate	480 Mbps
UASP Support	No
Hardware Raid Supported	No
Max Drive Capacity	Currently tested with up to 4TB 5400 RPM hard drives

---

### Connector(s)

Drive Connectors	1 - IDE (40 Pin, EIDE/PATA)
	1 - LP4 (4 pin; Large Drive Power)
	1 - SATA (7 pin, Data)
	1 - SATA Power (15 pin)
Host Connectors	1 - USB B (4 pin)

---

#### Software

OS Compatibility	OS independent; No software or drivers required
------------------	---

---

#### Power

Power Source	AC Adapter Included
Input Voltage	115V AC
Output Voltage	12V DC
Output Current	2A
Center Tip Polarity	Positive
Plug Type	L

---

#### Physical Characteristics

Color	Black
Material	Aluminum
Product Length	8.7 in [22.2 cm]
Product Width	1.5 in [3.8 cm]
Product Height	5.5 in [14.0 cm]
Weight of Product	26.4 oz [748.4 g]

---

#### Packaging Information

Package Length	11.2 in [28.5 cm]
Package Width	4.4 in [11.2 cm]
Package Height	7.0 in [17.8 cm]
Shipping (Package)	3.0 lb [1.4 kg]

Weight

---

**What's in the Box**

Included in Package	1 - SATA/IDE to USB 2.0 External HDD Enclosure
	1 - IDE Cable (Internal)
	1 - USB 2.0 Cable
	1 - SATA Data Cable (Internal)
	1 - SATA Power Adapter Cable (Internal)
	1 - LP4 Power Adapter Cable (Internal)
	1 - Mounting Screw Kit
	1 - AC Power Adapter
	1 - Instruction Manual

---

**Warranty Information**

Warranty	2 Years
----------	---------

---

*\*Product appearance and specifications are subject to change without notice.*