

2-ports USB 2.0 över Cat5 eller Cat6-förlängarpaket - strömförsörjning lokalt eller på
distans - 100 m - USB-förlängare - USB till Ethernet

Produkt ID: USB2002EXT2




The USB2002EXT2 2-Port USB Extender lets you extend USB 2.0 devices over Cat 5 or better Ethernet cable at distances of up to 330ft (100m). A local transmitter power adapter provides up to 500 mA of power per port with no power adapter required at the remote end, letting you access and power almost any USB 2.0 device in locations where a power outlet may be unavailable.

This USB extender provides support for data transfer rates of up to 480 Mbps, is Plug-and-Play and hot-swap compatible, and is also backwards compatible with USB 1.x devices.

This versatile USB extender offers a fast, easy, and flexible solution for business or industrial applications with durable metal housing, and an included surface-mounting bracket kit.

Backed by a StarTech.com 2-year warranty and free lifetime technical support.

Certifikat, rapporter och kompatibilitet

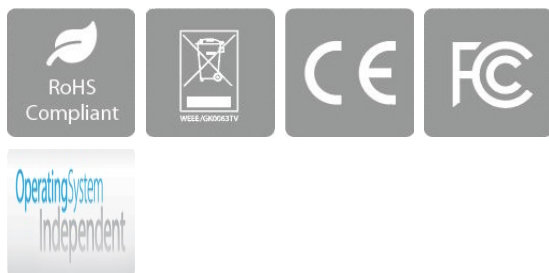

Användning

- Secured environments where the host computer must be in a secure, inaccessible location from the keyboard, mouse, camera or other USB input devices
- Use existing in-wall Cat5/Cat6 wiring to extend USB connections between rooms
- Reduce cable clutter and the need for mid-point USB hubs/repeaters by running a single, easy-to-install Cat5/Cat6 cable
- Industrial control environments where the host computer must be located away from interference or contamination

Funktioner

- NYARE VERSION USB2002EXT2NA endast tillgänglig i Nordamerika; Förläng två USB 2.0-anslutningar med ström med upp till 100 m över Cat5- eller Cat6-kabel
- Two USB 2.0 ports on remote unit over a single Cat5/Cat6 cable
- Maximum extension distance of up to 100m (330ft) over Cat5 cabling
- Rugged, metal enclosure with surface-mounting bracket kit included
- High Speed USB 2.0 compliant with support for data transfer rates up to 480 Mbps
- 500mA of power per port
- No external power required at remote end as power is delivered over Cat5/Cat6
- 4kV Contact and 8kV Air Electrical Static Discharge (ESD) protection
- No driver or software required
- Plug-and-Play and hot-swap compatible

Hårdvara

Garantipolicy	2 Years
Portar	2
Kablage	Cat 5 UTP

Prestanda

Maximal dataöverföringshastighet	480 Mbps
Maximalt avstånd	100m [328ft]

Kontakt(er)		
	Lokala enhetskontakter	1 - RJ-45
		1 - USB B (4-stifts)
	Fjärrenhetskontakter	1 - RJ-45
		2 - USB 2.0 Type-A (4 stift, 480 Mbps)
Mjukvara		
	OS-kompatibilitet	OS Independent; No additional drivers or software required
Särskilda anmärkningar/krav		
	System- och kabelkrav	USB enabled computer system with available USB port
Ström		
	Strömkälla	AC-adapter medföljer
	Inspänning	100 - 240 AC
	Inström	0.6 A
	Utspänning	24 DC
	Utström	1.0 A
	Polaritet på mittpol	Positiv
	Kontakttyp	M
	Strömförbrukning	24
Miljö		
	Drifttemperatur	0°C to 50°C (32°F to 122°F)
	Förvaringstemperatur	-20°C to 70°C (-4°F to 158°F)
	Luftfuktighet	10~90% RH
Utseende		
	Färg	Svart

Kabinetttyp	Aluminium och plast
Produktlängd	3.9 in [10.0 cm]
Produktbredd	3.0 in [7.6 cm]
Produkthöjd	1.0 in [2.6 cm]
Produktvikt	1.3 lb [0.6 kg]

Förpackning

Förpackningsantal	1
Paketets längd	9.8 in [24.8 cm]
Paketets bredd	7.7 in [19.5 cm]
Paketets höjd	4.3 in [10.8 cm]
Fraktvikt (förpackning)	2.6 lb [1.2 kg]

Vad det är i lådan

Ingår i paketet	1 - USB 2.0 extender local unit
	1 - USB 2.0 extender remote unit
	1 - USB cable
	1 - mounting kit
	1 - universal power adapter (NA, JP, EU, UK, ANZ)
	1 - quick-start guide

Warranty Information

Warranty	2 År
----------	------

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.