

6ft (1.8m) USB to DVI Adapter Cable – M/M - 1920x1200

Produkt ID: USB2DVIMM6




The USB2DVIMM6 External USB DVI Adapter Cable offers a hassle-free multi-monitor solution, turning a USB 2.0 port into a DVI video connection. This 6-foot USB Display Adapter is a complete solution, ready to go out of the box with all the cables you need built right onto the adapter. Simply install the drivers, connect to your computer and display. Built-on cables make the USB2DVIMM6 easier to install and does away with the need to worry about forgetting a cable.

Instead of having to open the computer case to install a specialized video card to accommodate a multi-display configuration, USB2DVIMM6 functions as an external USB video card saving both time and hassle.

Multiple (USB2DVIMM6) adapters (up to 5 total) can be used on a single system to provide several mirrored displays or extended desktops - a convenient and cost-effective multi-VGA option for virtually any laptop or desktop operating environment.

Backed by a StarTech.com 2-year warranty and free lifetime technical support.

Certifikat, rapporter och kompatibilitet

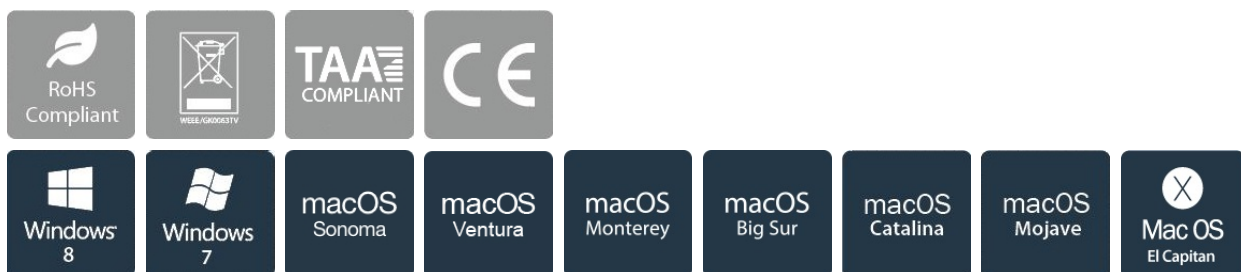



Användning

- Extend or mirror the image shown on an existing display
- Run multiple applications on different screens, check your email on one display and work on a document in the other.

Funktioner

- Optimal performance at 1680x1050 and ideal for use with 20" to 22" monitors or smaller
- Built-on USB and DVI cables
- Hassle-free installation
- No power adapter required
- Supports the use of DVI to VGA or DVI to HDMI adapters

Hårdvara

Garantipolicy	2 Years
AV-ingång	USB 2.0
AV-utgång	DVI
USB-passthrough	Nej
Minne	16MB
Chipset-ID	DisplayLink - DL-165

Prestanda

Maximal digital upplösning	1600x1200(standard) or 1680x1050(wide) @ 32 bits
Stödda upplösningar	Widescreen (16/32 bit): 1680x1050, 1440x900, 1366x768

		Standard (16/32 bit):
		1600x1200, 1280x1024, 1024x768, 800x600, 640x480
	Medeltid mellan fel (MTBF)	59,000 hours
Kontakt(er)	Connector A	1 - USB 2.0 Type-A (4 stift, 480 Mbps)
	Connector B	1 - DVI-D (19-stifts)
Mjukvara	OS-kompatibilitet	Windows® XP (32-bit), Vista, 7, 8/8.1, 10
		macOS 10.6 to 10.12, 10.14 - 10.15, 11.0, 12.0, 13.0, 14.0, 15.0
		Ubuntu 18.04, 20.04, 22.04
		Chrome OS v51
	Microsoft WHQL-certifierad	Ja
Särskilda anmärkningar/krav		
	System- och kabelkrav	System Processor: 1.2GHz
		System Memory: 512MB
	Obs.	Connect a maximum of five USB video adapters on a single computer. Support for multiple adapters will vary depending upon your system resources
		This USB video adapter is not intended for graphical intensive applications, such as gaming
Utseende		
	Färg	Svart
	Kabellängd	6.0 ft [1.8 m]
	Produktlängd	6.0 ft [1.8 m]
	Produktbredd	1.9 in [4.8 cm]
	Produkthöjd	0.9 in [2.4 cm]

	Produktvikt	3.5 oz [100.0 g]
Förpackning		
	Paketets längd	6.6 in [16.8 cm]
	Paketets bredd	2.6 in [6.5 cm]
	Paketets höjd	5.7 in [14.6 cm]
	Fraktvikt (förpackning)	10.6 oz [300.0 g]
Vad det är i lådan		
	Ingår i paketet	1 - USB to DVI Cable Adapter
		1 - Driver CD
		1 - Instruction Manual
Warranty Information		
	Warranty	2 År

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.