

USB to DVI Adapter - 1920x1200

Product ID: USB2DVIPRO2




The USB2DVIPRO2 USB to DVI Adapter functions as an external graphics card for Windows and Mac computers - the perfect solution for turning your desktop or laptop computer into a dual or multi-monitor environment, all through the simplicity and convenience of USB.

The USB-DVI Adapter delivers high quality video (up to 1920x1200) for a variety of applications and is capable of simultaneously running up to five additional displays from a single computer (using four USB2DVIPRO2 External Video Adapters). The adapter connects to a host computer through a USB 2.0 port, acting as an external DVI video card to either extend or mirror the desktop shown on the existing display - without having to open the computer case.

Featuring driver support for Microsoft Windows (including Aero themes) and Mac OS X, and with video support for resolutions up to 1920x1200, this USB-DVI video adapter is the ideal solution for a wide range of operating environments as well as large-screen displays/monitors.

The USB2DVIPRO2 USB to DVI Adapter is backed by a StarTech.com 2-year warranty and free lifetime technical support.

Certifications, Reports and Compatibility

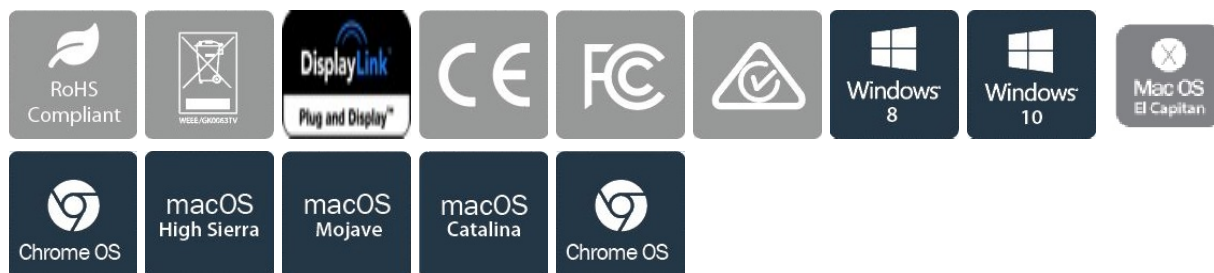

Applications

- Add multiple (up to five) monitors / projectors to your computer setup using one USB2DVIPRO2 device for each

additional display

- View large or multiple spreadsheets across multiple displays
- Increase productivity by running multiple applications on different DVI screens; check your email on one display while editing a document on the other
- Use the USB-DVI adapter to connect your PC to your television for showing family pictures and movies
- Connect multiple DVI monitors to a single computer to create engaging multimedia presentations
- Great for researchers and writers offering the ability to have reference material on one display and a working document copy on the other

Features

- Support for Aero themes in Windows
- Optimal performance at 1920x1200 and ideal for use with 24" to 26" monitors or smaller
- USB-Powered operation, no external power adapter required
- Works with Mac OS X
- Quick and easy installation
- Powered by DisplayLink DL-195 chip

Hardware	Warranty	2 Years
	AV Input	USB 2.0
	AV Output	DVI
	USB Pass-Through	No
	Memory	16MB
	Chipset ID	DisplayLink - DL-195
Performance	Maximum Digital Resolutions	1920x1200 (32-bit color)
	Supported Resolutions	Widescreen (16/32 bit): 1920x1200, 1680x1050, 1440x900, 1366x768
	General Specifications	
	MTBF	Standard (16/32 bit): 1600x1200, 1280x1024, 1024x768, 800x600, 640x480 This USB video adapter uses a DisplayLink family chipset. If you're connecting this device to a computer along with additional USB video adapters or docking stations, please avoid using devices with a Trigger or Fresco family chipset. 621,445 Hours
Connector(s)	Connector Type(s)	DVI-I (29 pin)
	Connector Type(s)	USB Type-A (4 pin) USB 2.0
Software	OS Compatibility	Windows 2000, XP, Vista, 7, 8, 8.1, 10

macOS 10.6 - 10.12, 10.14 - 10.15

Chrome OS v55+

Ubuntu 14.04, 16.04, 18.04

Special Notes / Requirements	System and Cable Requirements	System Processor: 1.2GHz
	Note	System Memory: 512MB
	Note	Power PC-based Macintosh computers, such as late-model iMacs, PowerBooks and PowerMacs, are not currently supported
	Note	This USB video adapter uses a DisplayLink family chipset. If you're connecting this device to a computer along with additional USB video adapters or docking stations, avoid using devices with different family chipsets, such as Trigger or Fresco Logic
	Note	Connect a maximum of five USB video adapters on a single computer. Support for multiple adapters will vary depending upon your system resources
		This USB video adapter is not intended for graphical intensive applications, such as gaming

Indicators	LED Indicators	Blue - Power
-------------------	----------------	--------------

Power	Power Source	USB-Powered
--------------	--------------	-------------

Environmental	Operating Temperature	10C to 40C (50F to 104F)
	Storage Temperature	-10C to 80C (14F to 176F)
	Humidity	<85% non-condensing

Physical Characteristics	Color	Black
	Cable Length	6.5 in [1.6 cm]
	Product Length	10.6 in [2.7 cm]
	Product Width	2.2 in [55 mm]
	Product Height	0.8 in [20 mm]
	Weight of Product	2.5 oz [70 g]

Packaging Information	Package Length	5.7 in [1.5 cm]
	Package Width	8.3 in [2.1 cm]
	Package Height	1.7 in [42 mm]
	Shipping (Package) Weight	8.6 oz [245 g]



What's in the Box	Included in Package	Driver CD
	Included in Package	Instruction Manual
	Included in Package	USB to DVI Adapter
	Included in Package	DVI to VGA adapter

****Product appearance and specifications are subject to change without notice.***

