

USB 3.0 Docking Station Dual Monitor with HDMI & 4K DisplayPort - USB 3.0 to 4x USB-A, Ethernet, HDMI and DP - USB Type A Universal Laptop Docking Station for Mac & Windows

**Product ID:** USB3DOCKHDPC



This TAA compliant dual-monitor USB 3.0 docking station combines a 4-port USB 3.0 hub, headphone and microphone audio connectors, a USB fast-charge port, and a GbE RJ45 Port with Wake-on-LAN (WOL).

This 4K USB docking station supports DisplayPort plus HDMI dual video, or a single DP display at 4K Ultra HD resolutions (3840 x 2160p).

Maximum Supported Resolutions\*

\*Lower resolutions are also supported. For example, if the max is 3840 x 2160p (4K), it also supports 2560 x 1600p and 2560 x 1440p.

The built-in USB hub features four USB 3.0 ports for connecting extra peripherals such as external hard drives or a wired mouse as if they are connected directly to your laptop.

The USB 3.0 dock's always-on USB fast-charge port charges devices without a laptop connection and supports USB Battery Charging Specification 1.2 making it easy to charge your tablets and other mobile devices.

The integrated RJ45 Ethernet port supports speeds of 10/100/1000Mbps, giving you an instant connection to a reliable wired network.

This docking station with DisplayPort and HDMI is universally compatible, working with Mac and Windows USB 3.0 equipped laptops and includes a 2ft. USB 3.0 cable for quick setup.

StarTech.com laptop docking stations can be used for cost savings and faster deployment with just a single cable. This USB 3.0 docking station is backed by a competitive 3-year warranty and free lifetime multilingual Technical Support.

## Certifications, Reports and Compatibility

## Applications

- Classrooms
- Computer Labs
- Network and Systems Administration

## Features

- **FULL FEATURE DOCK:** USB 3.0 Type-A dock with dual monitor options (HDMI & DisplayPort), 4x USB-A 5Gbps ports (one Fast Charge), Gigabit Ethernet, headset audio port, and K-slot for securing the dock
- **FLEXIBLE DISPLAY SETUP:** This docking station supports different display options with dual monitors DP & HDMI (2048 x 1152p and 1920 x 1080p), single DP (4K 30Hz) OR single HDMI (up to 2560 x 1440p)
- **USB-A LAPTOP COMPATIBILITY:** This DisplayLink certified laptop computer docking station works with new or legacy laptops from brands like HP, Dell, Lenovo, Microsoft Surface Pro, and Chromebooks
- **WIDE OPERATING SYSTEM COMPATIBILITY:** This universal laptop docking station fully supports major operating systems like Windows, macOS, and Chrome OS
- **PLENTY OF USB PORTS:** This USB 3.0 port replicator has a 4-port downstream USB-A hub (5Gbps SuperSpeed) including one always-on BC 1.2 (1.5A) fast-charge port that can charge without a connected host

---

### Hardware

Warranty	3 Years
4K Support	Yes
Fast-Charge Port(s)	Yes
Displays Supported	2
Bus Type	USB 3.0
Industry Standards	IEEE 802.3, IEEE 802.3u, IEEE 802.3ab USB Battery Charging Specification Rev. 1.2 USB 3.0 - Hub ports support USB 2.0/1.1 backward-compatibility
Chipset ID	DisplayLink - DL-5900 VIA/VLI - VL812

---

### Performance

Maximum Data Transfer	5 Gbps (USB 3.0)
-----------------------	------------------

Rate	2 Gbps (Ethernet; Full-Duplex)
Maximum Digital Resolutions	3840x2160 @ 30Hz / 2560x1600 / 2560x1440 (DisplayPort - Single Display)
	2560x1440 (HDMI - Single Display)
	2048x1152 & 2048x1152 (DisplayPort & HDMI - Two Displays)
	Lower resolutions are also supported.
Type and Rate	USB 3.0 - 5 Gbit/s
UASP Support	Yes
Compatible Networks	10/100/1000 Mbps
Auto MDIX	Yes
Full Duplex Support	Yes

---

#### Connector(s)

Connector Type(s)	DisplayPort (20 pin)
	HDMI (19 pin)
	USB 3.0 A (Fast-Charge, 9 pin)
	USB Type-A (9 pin) USB 3.0 (5 Gbps)
	RJ-45
	3.5 mm Mini-Jack (4 Position)
	USB Type-B (9 pin) USB 3.0
	Security Lock Slot


---

#### Software

OS Compatibility	Windows 7, 8, 8.1, 10
	macOS 10.8 - 10.12, 10.14 - 10.15, 11.0
	Chrome OS v55+

---

#### Special Notes / Requirements

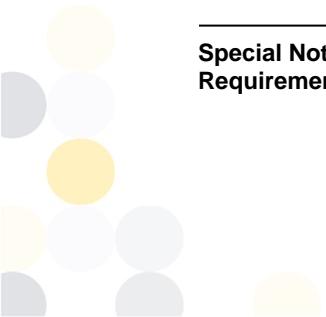

System and Cable Requirements

DisplayPort display must support 4K resolutions

If connected to a USB 2.0 host port, or if using a USB 2.0 host connection cable, performance may be limited (USB 3.0 host cable included)

**Indicators**

LED Indicators	Link (Green)
	Activity (Yellow)

**Power**

Power Source	AC Adapter Included
Input Voltage	100 - 240 AC
Input Current	1.5 A
Output Voltage	5 DC
Output Current	6.5 A
Plug Type	4-pin DIN
Power Consumption (In Watts)	32.5

**Environmental**

Operating Temperature	0C to 40C (32F to 104F)
Storage Temperature	-10C to 80C (14F to 176F)
Humidity	90% RH

**Physical Characteristics**

Color	Black
Material	Steel
Cable Length	24.0 in [60.9 cm]
Product Length	8.9 in [22.7 cm]
Product Width	3.0 in [76.0 mm]
Product Height	0.9 in [24.0 mm]



Weight of Product 9.8 oz [277.0 g]

---

**Packaging Information**

Package Length 7.8 in [19.8 cm]

Package Width 9.9 in [25.1 cm]

Package Height 2.8 in [71.0 mm]

Shipping (Package) Weight 2.4 lb [1.1 kg]

---

**What's in the Box**

Included in Package

- USB 3.0 Laptop Docking Station
- 2ft USB 3.0 Cable
- Universal Power Adapter
- Power Cords (NA/JP, EU, UK)
- Instruction Manual

---

***\*Product appearance and specifications are subject to change without notice.***

