

USB 3.0 to SATA III Adapter for 2.5in or 3.5in Drives

Produkt ID: USB3S2SATA3




The USB3S2SATA3 USB 3.0 to SATA Adapter/Converter connects a bare 2.5in or 3.5in SATA (6Gbps) Hard Drive (HDD) or Solid State Drive (SSD) to a computer through SuperSpeed USB 3.0.

The adapter is backward compatible with USB 2.0 hosts, as well as SATA I/II drives, and eliminates the need to connect a drive enclosure or HDD dock, making it the perfect tool for quickly connecting a bare SATA drive, in order to backup or retrieve data to/from the drive.

The USB 3.0/SATA III adapter features a convenient built-in Backup feature that when combined with the easy-to-use software (included), will launch the backup utility at the touch of a button.

The USB 3.0/SATA adapter works with Windows®, Linux, and Mac® computers and does not require any driver installation - a true plug-and-play solution, backed by a StarTech.com 2-year warranty and free lifetime technical support.

Certifikat, rapporter och kompatibilitet

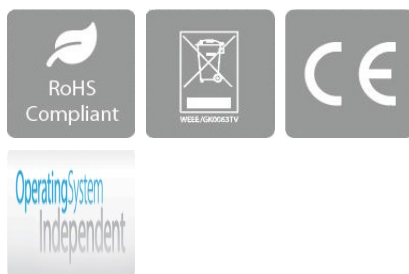

Användning

- Easily connect and access data from a 2.5in or 3.5in HDD or SSD using SuperSpeed USB 3.0
- Retrieve data from a drive without having to connect the drive internally

Funktioner

- SuperSpeed USB 3.0 compliant host interface, with transfer rates up to 5Gbps
- Supports both 2.5in and 3.5in SATA Hard Drives (HDD) and Solid State Drives (SSD)
- Compliant with SATA III and USB 3.0 rev. 1.0 specifications
- One Touch Backup (OTB) button with included backup software
- Backward compatible with SATA I/II Drives
- UASP support
- Power/Activity LED indicator
- Hot-Swap and Plug-and-Play Compatible

Hårdvara

Garantipolicy	2 Years
Gränssnitt	USB 3.2 Gen 1 (5 Gbps)
Busstyp	USB 3.2 Gen 1 (5 Gbps)
Antal enheter	1
Enhets typ	SATA
Chipset-ID	ASMedia - ASM1051E
LBA-stöd	48-bit

Prestanda

Typ och hastighet	USB 3.0 - 5 Gbit/s
UASP-stöd	Ja
Typ och hastighet	SATA III (6 Gbps)
Maximal enhetskapacitet	Currently tested up to 4TB

Kontakt(er)	Enhetskontakter	1 - SATA data- & ström-kombo (7+15-stifts)
	Värdkontakter	1 - USB 3.2 Type-B (9 stift, Gen 1, 5 Gbps)
Mjukvara	OS-kompatibilitet	OS independent; No software or drivers required
Särskilda anmärkningar/krav	System- och kabelkrav	Host computer system with available USB port (USB 3.0 recommended)
Indikatorer	LED-indikatorer	1 - Amber - Power (solid) /Activity (flashing)
Ström	Strömkälla	AC-adapter medföljer
	Inspänning	110V-240V AC
	Inström	0.6A
	Utspanning	12V DC
	Utström	1.5
	Polaritet på mittpol	Positiv
	Kontakttyp	M
Miljö	Drifttemperatur	0°C ~ 50°C (32°F ~ 122°F)
	Förvaringstemperatur	20°C ~ 60°C (68°F ~ 140°F)
	Luftfuktighet	5% ~ 85% RH
Utseende	Färg	Svart
	Kabinettyp	Av plast
	Produktlängd	2.7 in [69.4 mm]

Produktbredd	1.9 in [4.7 cm]
Produkthöjd	0.9 in [2.2 cm]
Produktvikt	1.2 oz [32.7 g]

Förpackning

Förpackningsantal	1
Paketets längd	9.1 in [23 cm]
Paketets bredd	6.2 in [15.7 cm]
Paketets höjd	2.2 in [55 mm]
Fraktvikt (förpackning)	12.5 oz [354 g]

Vad det är i lådan

Ingår i paketet	1 - USB 3.0 to SATA Converter
	1 - USB 3.0 A to B cable
	1 - Universal Power Adapter
	3 - Power Adapter Plug (NA/ UK/ EU)
	1 - Software CD
	1 - Instruction Manual

Warranty Information

Warranty	2 År
----------	------

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.