

USB 3.0 to SATA III Adapter for 2.5in or 3.5in Drives

Product ID: USB3S2SATA3



The USB3S2SATA3 USB 3.0 to SATA Adapter/Converter connects a bare 2.5in or 3.5in SATA (6Gbps) Hard Drive (HDD) or Solid State Drive (SSD) to a computer through SuperSpeed USB 3.0.

The adapter is backward compatible with USB 2.0 hosts, as well as SATA I/II drives, and eliminates the need to connect a drive enclosure or HDD dock, making it the perfect tool for quickly connecting a bare SATA drive, in order to backup or retrieve data to/from the drive.

The USB 3.0/SATA III adapter features a convenient built-in Backup feature that when combined with the easy-to-use software (included), will launch the backup utility at the touch of a button.

The USB 3.0/SATA adapter works with Windows, Linux, and Mac computers and does not require any driver installation - a true plug-and-play solution, backed by a StarTech.com 2-year warranty and free lifetime technical support.

Certifications, Reports and Compatibility

Applications

- Easily connect and access data from a 2.5in or 3.5in HDD or SSD using SuperSpeed USB 3.0
- Retrieve data from a drive without having to connect the drive internally

Features

- SuperSpeed USB 3.0 compliant host interface, with transfer rates up to 5Gbps
- Supports both 2.5in and 3.5in SATA Hard Drives (HDD) and Solid State Drives (SSD)

- Compliant with SATA III and USB 3.0 rev. 1.0 specifications
- One Touch Backup (OTB) button with included backup software
- Backward compatible with SATA I/II Drives
- UASP support
- Power/Activity LED indicator
- Hot-Swap and Plug-and-Play Compatible

Hardware

Warranty	2 Years
Interface	USB 3.0
Bus Type	USB 3.0
Number of Drives	1
Compatible Drive Types	SATA
Chipset ID	ASMedia - ASM1051E
LBA support	48-bit

Performance

Type and Rate	USB 3.0 - 5 Gbit/s
UASP Support	Yes
Type and Rate	SATA III (6 Gbps)
Max Drive Capacity	Currently tested up to 4TB

Connector(s)


Drive Connectors	SATA Data & Power Combo (7+15 pin)
Host Connectors	USB Type-B (9 pin) USB 3.0

Software

OS Compatibility	OS independent; No software or drivers required
------------------	---

Special Notes / Requirements

System and Cable	Host computer system with available USB port (USB 3.0)
------------------	--

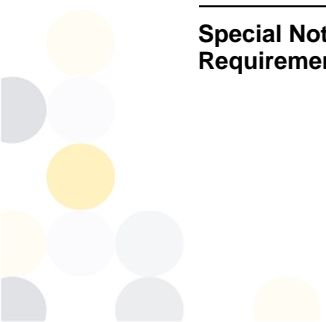

	Requirements	recommended)
Indicators		
	LED Indicators	Amber - Power (solid) /Activity (flashing)
Power		
	Power Source	AC Adapter Included
	Input Voltage	110V-240V AC
	Input Current	0.6A
	Output Voltage	12V DC
	Output Current	1.5
	Center Tip Polarity	Positive
	Plug Type	M
Environmental		
	Operating Temperature	0C ~ 50C (32F ~ 122F)
	Storage Temperature	20C ~ 60C (68F ~ 140F)
	Humidity	5% ~ 85% RH
Physical Characteristics		
	Color	Black
	Material	Plastic
	Product Length	2.7 in [69.4 mm]
	Product Width	1.9 in [47.3 mm]
	Product Height	0.9 in [21.6 mm]
	Weight of Product	1.2 oz [32.7 g]
Packaging Information		
	Package Length	9.1 in [23 cm]
	Package Width	6.2 in [15.7 cm]
	Package Height	2.2 in [55 mm]



Shipping (Package) Weight	12.5 oz [354 g]
------------------------------	-----------------

What's in the Box

Included in Package	USB 3.0 to SATA Converter
	USB 3.0 A to B cable
	Universal Power Adapter
	Power Adapter Plug (NA/ UK/ EU)
	Software CD
	Instruction Manual

****Product appearance and specifications are subject to change without notice.***

