


6 ft SuperSpeed USB 3.0 (5Gbps) Cable A to A - M/M

Produkt ID: USB3SAA6

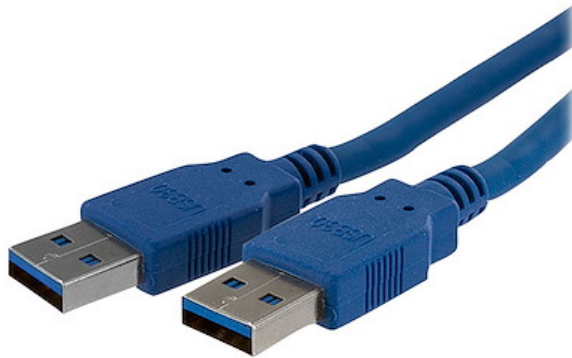

StarTech.com's 6ft SuperSpeed USB 3.2 Gen 1 cable (A-A) offers a durable, high quality connection that harnesses the full capability of the USB 3.2 Gen 1 standard.

Designed for next-generation SuperSpeed USB device connections, this USB 3.2 Gen 1 A to A Male/Male cable provides connectivity between a PC and hub or other USB A devices, delivering a throughput of up to 5Gbps when used with a USB 3.2 Gen 1 host and device - an astounding 10x the capability of USB 2.0 (480Mbps).

Our 6ft USB 3.2 Gen 1 A to A device cable features high quality Shielded Twisted Pair (STP) construction, helping to prevent electro-magnetic interference and ensuring reliable data communication.

The 6ft USB 3.2 Gen 1 device cable is backed by our Lifetime Warranty, providing guaranteed quality and reliability.

Certifikat, rapporter och kompatibilitet



Användning

- Connect a USB 3.0 SuperSpeed A devices such as a USB hub to a Desktop or Server

Funktioner

- Cable and Connectors are compliant with USB 3.2 Gen1 SuperSpeed specifications

Hårdvara

Garantipolicy	Lifetime
Kabelmanteltyp	PVC - Polyvinyl Chloride
Kabelskärmning	Folieskärmad partvinnad

Prestanda

Typ och hastighet	USB 3.0 - 5 Gbit/s
-------------------	--------------------

Kontakt(er)

Connector A	1 - USB Type-A (9-stifts) USB 3.0 (5 Gbps)
Connector B	1 - USB Type-A (9-stifts) USB 3.0 (5 Gbps)

Utseende

Färg	Blå
Tråddimension	28 AWG
Kabellängd	6.0 ft [1.8 m]
Produktlängd	6.0 ft [1.8 m]
Produktbredd	0.0 in [0.0 cm]
Produkthöjd	0.0 in [0.0 cm]
Produktvikt	2.5 oz [71.0 g]

Förpackning

Förpackningsantal	1
Paketets längd	5.5 in [13.9 cm]
Paketets bredd	7.8 in [19.7 cm]
Paketets höjd	1.0 in [2.5 cm]
Fraktvikt (förpackning)	2.8 oz [80.0 g]

Vad det är i lådan

Ingår i paketet

1 - USB A to A Male to Male cable

Warranty
Information

Warranty

Livslängd

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.