


10 ft SuperSpeed USB 3.0 Cable A to B - M/M

Produkt ID: USB3SAB10

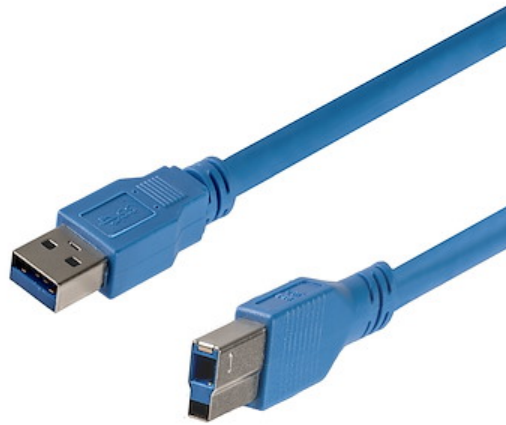

StarTech.com's 10ft USB 3.0 cable (A-B, male-male) offers a durable, high quality connection that harnesses the full capability of the USB 3.0 standard.

Designed for next-generation SuperSpeed USB device connections, the 10ft USB 3.0 cable offers a throughput of up to 5Gbps when used with a USB 3.0 host and device - an astounding 10x the capability of USB 2.0 (480Mbps).

Our 10ft USB 3.0 cable features high quality Shielded Twisted Pair (STP) construction, helping to prevent electro-magnetic interference and ensuring reliable data communication.

The 10ft USB 3.0 cable is backed by our Lifetime Warranty, providing guaranteed quality and reliability.

Certifikat, rapporter och kompatibilitet

Användning

Funktioner

- Cable and Connectors are compliant with USB 3.0 SuperSpeed specifications

Hårdvara

Garantipolicy

Lifetime

	Kabelmanteltyp	PVC - Polyvinyl Chloride
	Kabelskärmning	Folieskärmad partvinnad
<hr/>		
Prestanda		
	Typ och hastighet	USB 3.0 - 5 Gbit/s
<hr/>		
Kontakt(er)		
	Connector A	USB Type-A (9-stifts) USB 3.0 (5 Gbps)
	Connector B	USB Type-B (9-stifts) USB 3.0
<hr/>		
Utseende		
	Färg	Blå
	Tråddimension	28 AWG
	Kabellängd	10.0 ft [3.0 m]
	Produktlängd	10.0 ft [3.0 m]
	Produktbredd	0.0 in [0.0 mm]
	Produkt höjd	0.0 in [0.0 mm]
	Produktvikt	4.9 oz [137.4 g]
<hr/>		
Förpackning		
	Package Length	4.3 in [11.0 cm]
	Package Width	1.1 in [28.0 mm]
	Package Height	8.4 in [21.4 cm]
	Fraktvikt (förpackning)	5.0 oz [142.1 g]
<hr/>		
Vad det är i lådan		
	Ingår i paketet	10 ft SuperSpeed USB 3.0 Cable A to B - M/M
<hr/>		

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.

