


10 ft SuperSpeed USB 3.0 Cable A to B - M/M

Product ID: USB3SAB10

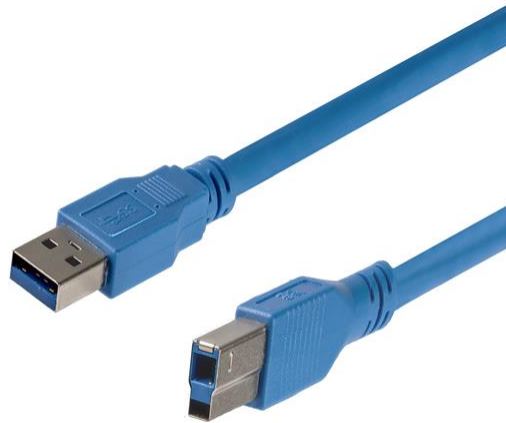

StarTech.com's 10ft USB 3.0 cable (A-B, male-male) offers a durable, high quality connection that harnesses the full capability of the USB 3.0 standard.

Designed for next-generation SuperSpeed USB device connections, the 10ft USB 3.0 cable offers a throughput of up to 5Gbps when used with a USB 3.0 host and device - an astounding 10x the capability of USB 2.0 (480Mbps).

Our 10ft USB 3.0 cable features high quality Shielded Twisted Pair (STP) construction, helping to prevent electro-magnetic interference and ensuring reliable data communication.

The 10ft USB 3.0 cable is backed by our Lifetime Warranty, providing guaranteed quality and reliability.

Certifications, Reports and Compatibility

Applications

Features

- Cable and Connectors our compliant with USB 3.0 SuperSpeed specifications

Hardware

Warranty	Lifetime
Cable Jacket Material	PVC - Polyvinyl Chloride
Cable Shield Material	Foil shielded twisted pair

Performance

Type and Rate	USB 3.0 - 5 Gbit/s
---------------	--------------------

Connector(s)

Connector A	USB Type-A (9 pin) USB 3.0 (5 Gbps)
Connector B	USB Type-B (9 pin) USB 3.0

Physical Characteristics

Color	Blue
Wire Gauge	28 AWG
Cable Length	10.0 ft [3.0 m]
Product Length	10.0 ft [3.0 m]
Product Width	0.0 in [0.0 mm]
Product Height	0.0 in [0.0 mm]
Weight of Product	4.9 oz [137.4 g]

Packaging Information

Package Length	4.3 in [11.0 cm]
Package Width	1.1 in [28.0 mm]
Package Height	8.4 in [21.4 cm]
Shipping (Package) Weight	5.0 oz [142.1 g]

What's in the Box

Included in Package	10 ft SuperSpeed USB 3.0 Cable A to B - M/M
---------------------	---------------------------------------------

****Product appearance and specifications are subject to change without notice.***

