


6 ft SuperSpeed USB 3.0 Cable A to B - M/M

Produkt ID: USB3SAB6

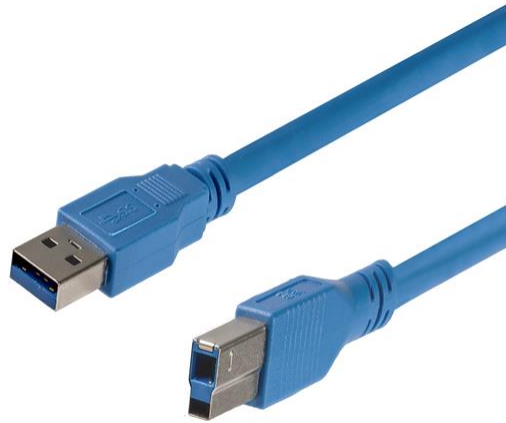

StarTech.com's 6ft USB 3.0 cable (A-B, male-male) offers a durable, high quality connection that harnesses the full capability of the USB 3.0 standard.

Designed for next-generation SuperSpeed USB device connections, the 6ft USB 3.0 cable offers a throughput of up to 5Gbps when used with a USB 3.0 host and device - an astounding 10x the capability of USB 2.0 (480Mbps).

Our 6ft USB 3.0 cable features high quality Shielded Twisted Pair (STP) construction, helping to prevent electro-magnetic interference and ensuring reliable data communication.

The 6ft USB 3.0 cable is backed by our Lifetime Warranty, providing guaranteed quality and reliability.

Certifikat, rapporter och kompatibilitet

Användning

- Superspeed 3.0 data transfer with USB 3.0 compliant devices

Funktioner

- Cable and Connectors our compliant with USB 3.0 SuperSpeed specifications

Garantipolicy	Lifetime
Kabelmanteltyp	PVC - Polyvinyl Chloride
Kabelskärmning	Folieskärmad partvinnad

Prestanda

Typ och hastighet	USB 3.0 - 5 Gbit/s
-------------------	--------------------

Kontakt(er)

Connector A	USB Type-A (9-stifts) USB 3.0 (5 Gbps)
Connector B	USB Type-B (9-stifts) USB 3.0

Miljö

Drifttemperatur	-10°C to 55°C (14°F to 131°F)
Förvaringstemperatur	-20°C to 60°C (-4°F to 140°F)
Luftfuktighet	20%-80% RH (non-condensing)

Utseende

Färg	Blå
Tråddimension	28 AWG
Kabellängd	6.0 ft [1.8 m]
Produktlängd	6.0 ft [1.8 m]
Produktbredd	0.0 in [0.0 mm]
Produkthöjd	0.0 in [0.0 mm]
Produktvikt	2.4 oz [68.0 g]

Förpackning

Package Length	8.7 in [22.0 cm]
Package Width	0.8 in [20.0 mm]
Package Height	0.6 in [16.0 mm]
Fraktvikt (förpackning)	2.7 oz [77.0 g]



Vad det är i
lådan

Ingår i paketet

6 ft SuperSpeed USB 3.0 Cable A to B - M/M

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.

