


## 3 ft Panel Mount USB Cable A to B - F/M

**Product ID:** USBPNLAFBM3

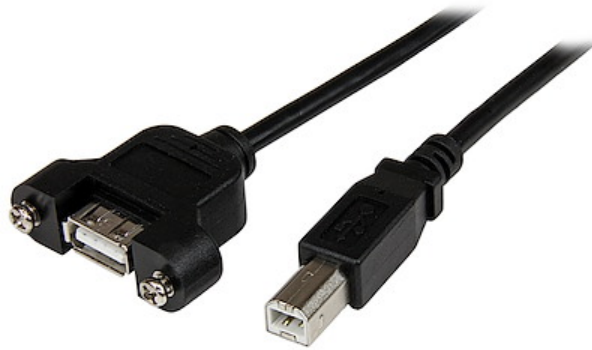

The USBPNLAFBM3 3ft Panel Mount USB-B Cable provides a well-secured, easy to access USB-A port on your PC or on a faceplate, allowing you to customize your systems to suit your needs. Perfect for podiums, kiosks and other solutions where added access to USB peripherals is required.

The adapter features one male USB-B connector and one female panel mount USB-A port allowing you to mount your USB device internally enabling you to access it through a USB-A connection. Offering 3ft in cable length, the adapter allows you to place the cable as needed within the system case.

The USBPNLAFBM3 is backed by StarTech.com's lifetime warranty for guaranteed reliability.

## Certifications, Reports and Compatibility



## Applications

- Add a USB-A female panel mount port connected to an internal/external USB-B device

## Features

- 1x USB-B male connector
- 1x USB-A panel mount female port
- Offers 3' in cable length

---

## Hardware

Warranty	Lifetime
Connector Plating	Nickel
Cable Jacket Material	PVC - Polyvinyl Chloride
Cable Shield Material	Aluminum-Mylar Foil with Braid

---

## Connector(s)

Connector A	1 - USB 2.0 Type-A (4 pin, 480Mbps)
Connector B	1 - USB B (4 pin)

---

## Physical Characteristics

Color	Black
Connector Style	Straight
Wire Gauge	24/28 AWG
Cable Length	3.0 ft [0.9 m]
Product Length	3.0 ft [0.9 m]
Weight of Product	1.4 oz [40 g]

---

## Packaging Information

Package Quantity	1
Package Length	8.9 in [22.5 cm]
Package Width	4.9 in [12.5 cm]
Package Height	0.4 in [10 mm]
Shipping (Package) Weight	1.6 oz [46 g]

---

## What's in the Box

Included in Package	1 - 3 ft Panel Mount USB Cable A to B - F/M
---------------------	---

---

## Warranty Information

Warranty

Lifetime

---

***\*Product appearance and specifications are subject to change without notice.***