

Universal Laptop USB Docking Station with VGA Audio Ethernet

Product ID: USBVGADOCK2



The USBVGADOCK2 is a TAA-compliant combination USB VGA adapter and 4-in-1 docking station that converts a single USB 2.0 port into multiple connection ports, including: a VGA port, 10/100 RJ45 network connection, dual (3.5mm phono) audio ports and four additional USB 2.0 ports.

Compatible with a broad range of operating systems, including Microsoft Windows 7, the USB VGA adapter/docking station supports 1600x1200 (32-bit) display resolutions for connected VGA monitors and saves the time and hassle of having to disconnect devices like speakers and USB peripherals (scanners, printers, webcams etc.) in order to re-connect them to another computer. Using this convenient docking station makes it as simple as creating the single USB 2.0 host connection in order to access the connected peripherals.

The USBVGADOCK2 is backed by a StarTech.com 3-year warranty and free lifetime technical support.

Certifications, Reports and Compatibility

Applications

- Add video outputs to a laptop or small form factor computer without adding or replacing the video card
- Add video, USB, Ethernet and Audio from a single USB connection, without having to open the computer system

Features

- External monitor connection via a VGA port
- Maximum VGA video resolution up to 1600x1200 at 32-bit color
- Speaker and Microphone support via 3.5mm stereo mini-jacks

- 10/100Mbps RJ-45 Ethernet port
- Built-in 4-port USB 2.0 hub
- High Speed USB 2.0 compliant with transfer rates up to 480Mbps
- Small, portable form factor
- Includes a universal power adapter with power connectors for North America, United Kingdom, and Europe
- TAA Compliant

Hardware

Warranty	3 Years
4K Support	No
Fast-Charge Port(s)	No
Displays Supported	1
Audio	Yes
Bus Type	USB 2.0
Industry Standards	IEEE 802.3, IEEE 802.3u
Chipset ID	SMSC - LAN9500 Trigger - UV-185CB-128

Performance

Maximum Data Transfer Rate	10/100 Mbps (Ethernet) 480 Mbps (USB 2.0)
Maximum Analog Resolutions	1600x1200 @ 32 bits Lower resolutions are also supported.
Type and Rate	USB 2.0 - 480 Mbit/s
Compatible Networks	10/100 Mbps
Full Duplex Support	Yes

Connector(s)

Connector Type(s)	VGA (15 pin, High Density D-Sub)
-------------------	----------------------------------



3.5 mm Mini-Jack (3 Position)

RJ-45

USB Type-A (4 pin) USB 2.0

USB Mini-B (5 pin)

Software

OS Compatibility	Windows 10 (32-bit or 64-bit), 8 / 8.1 (32-bit or 64-bit), 7 (32-bit or 64-bit), Vista (32-bit or 64-bit), XP (32-bit or 64-bit)
------------------	--

Power

Power Source	AC Adapter Included
Input Voltage	115V-230V AC
Output Voltage	5 DC
Output Current	3A
Center Tip Polarity	Positive
Plug Type	M
Power Consumption (In Watts)	15


Environmental

Operating Temperature	15C to 30C (59F to 86F)
Storage Temperature	0C to 70C (32F to 158F)

Physical Characteristics

Color	Black
Material	Plastic
Product Length	8.0 in [20.3 cm]
Product Width	2.7 in [69.8 mm]
Product Height	0.8 in [19.1 mm]
Weight of Product	7.3 oz [208 g]

Packaging Information

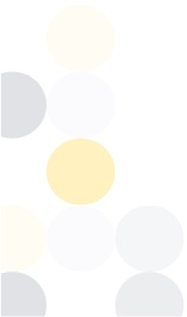

Package Length	7.1 in [18 cm]
Package Width	9.1 in [23.2 cm]
Package Height	2.2 in [56 mm]
Shipping (Package) Weight	21.5 oz [608 g]

What's in the Box

Included in Package	USB VGA Dock
	Universal power adapter: comes ready for NA/EU/UK only when you buy in NA/EU/UK; comes ready for Australia and New Zealand only when you buy in Australia and New Zealand
	Instruction Manual
	3.3 ft [1016 mm] USB Cable

****Product appearance and specifications are subject to change without notice.***

