


10 ft Micro USB Cable - A to Micro B

Produkt ID: UUSBHAUB10

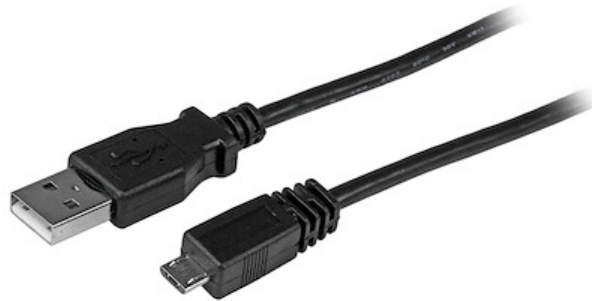

The UUSBHAUB10 10-foot USB A to Micro USB cable features one USB 'A' male connector, and one 'Micro-B' male connector, providing a high quality connection to USB 2.0 mobile devices (such as BlackBerry® or Android-based cellular phones, digital cameras, PDA's, Tablet PC devices and GPS systems) that use a Micro USB connector to a USB capable computer for everyday tasks such as data synchronization and file transfers.

This high quality cable is backed by StarTech.com's Lifetime Warranty to ensure dependable, long-lasting connections between Micro USB and USB devices.

Certifikat, rapporter och kompatibilitet

Användning

- An ideal replacement cable for connecting mobile devices to a USB capable computer

Funktioner

- Supports high speed data transfer rates up to 480 Mbps
- Aluminum-Mylar Foil with Braided Shielding
- High quality USB 'A' and USB 'Micro-B'connectors
- Durable PVC construction

Hårdvara

Garantipolicy	Lifetime
Kontaktplätering	Nickel
Kabelmanteltyp	PVC - Polyvinyl Chloride
Kabelskärmning	Aluminiummylarfolie med flätning

Prestanda

Typ och hastighet	USB 2.0 - 480 Mbit/s
-------------------	----------------------

Kontakt(er)

Connector A	USB Type-A (4-stifts) USB 2.0
Connector B	USB Micro-B (5-stifts)

Miljö

Drifttemperatur	-20°C to 60°C (-4°F to 140°F)
Förvaringstemperatur	-10°C to 30°C (14°F to 86°F)
Luftfuktighet	30%-75% RH

Utseende

Färg	Svart
Tråddimension	24/30 AWG
Kabellängd	10.0 ft [3.0 m]
Produktlängd	10.0 ft [3.0 m]
Produktbredd	0.6 in [16.0 mm]
Produkt höjd	0.3 in [7.0 mm]
Produktvikt	2.4 oz [68.0 g]

Förpackning

Package Length	8.9 in [22.5 cm]
Package Width	4.9 in [12.5 cm]



Package Height 0.0 in [0.1 mm]

Fraktvikt (förpackning) 2.5 oz [72.0 g]

Vad det är i lådan

Ingår i paketet 10 ft Micro USB Cable - A to Micro B

* Produkters utseende och specifikationer kan komma att ändras utan förvarning.

