


10 ft Micro USB Cable - A to Micro B

Product ID: UUSBHAUB10

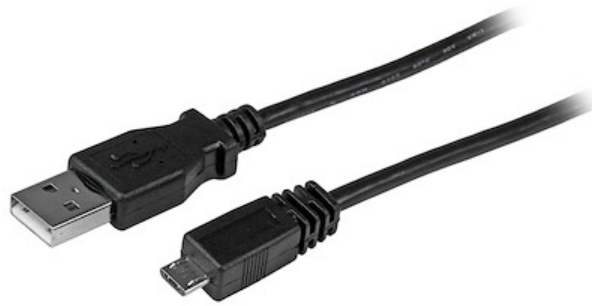

The UUSBHAUB10 10-foot USB A to Micro USB cable features one USB 'A' male connector, and one 'Micro-B' male connector, providing a high quality connection to USB 2.0 mobile devices (such as BlackBerry or Android-based cellular phones, digital cameras, PDA's, Tablet PC devices and GPS systems) that use a Micro USB connector to a USB capable computer for everyday tasks such as data synchronization and file transfers.

This high quality cable is backed by StarTech.com's Lifetime Warranty to ensure dependable, long-lasting connections between Micro USB and USB devices.

Certifications, Reports and Compatibility

Applications

- An ideal replacement cable for connecting mobile devices to a USB capable computer

Features

- Supports high speed data transfer rates up to 480 Mbps
- Aluminum-Mylar Foil with Braided Shielding
- High quality USB 'A' and USB 'Micro-B' connectors
- Durable PVC construction

Hardware

Warranty	Lifetime
Connector Plating	Nickel
Cable Jacket Material	PVC - Polyvinyl Chloride
Cable Shield Material	Aluminum-Mylar Foil with Braid

Performance

Type and Rate	USB 2.0 - 480 Mbit/s
---------------	----------------------

Connector(s)

Connector A	USB Type-A (4 pin) USB 2.0
Connector B	USB Micro-B (5 pin)

Environmental

Operating Temperature	-20C to 60C (-4F to 140F)
Storage Temperature	-10C to 30C (14F to 86F)
Humidity	30%-75% RH

Physical Characteristics

Color	Black
Wire Gauge	24/30 AWG
Cable Length	10.0 ft [3.0 m]
Product Length	10.0 ft [3.0 m]
Product Width	0.6 in [16.0 mm]
Product Height	0.3 in [7.0 mm]
Weight of Product	2.4 oz [68.0 g]

Packaging Information

Package Length	8.9 in [22.5 cm]
Package Width	4.9 in [12.5 cm]
Package Height	0.0 in [0.1 mm]
Shipping (Package)	2.5 oz [72.0 g]



Weight

What's in the Box

Included in Package	10 ft Micro USB Cable - A to Micro B
---------------------	--------------------------------------

****Product appearance and specifications are subject to change without notice.***

