

2 Port DisplayPort Video Switch with Audio & IR Remote Control

Product ID: VS221DP



The VS221DP 2 Port DisplayPort Video Switch with Audio & IR Remote Control offers a reliable solution for switching between multiple DisplayPort audio/video sources for demanding high-resolution applications.

Supporting a native display resolution of 2560x1600 and 7.1 channel audio (when connected to supporting displays and sources), this simple, yet comprehensive DisplayPort A/V Switch features both push-button and infrared remote control source selection, and offers a compact form factor design.

Backed by a StarTech.com 2-year warranty and free lifetime technical support.

Certifications, Reports and Compatibility

Applications

- High resolution digital images in education in the classroom, lecture halls, and conference rooms with multiple sources to one DisplayPort monitor
- Multimedia design, multimedia post-production and video editing
- High resolution digital signage requiring multiple sources with one display
- High resolution medical imaging and Health care display, such as MRI and X-Ray display

Features

- Supports resolutions up to 2560 x 1600 @ 60Hz, beyond 1080p
- 7.1 Channel High Definition Audio pass-through (with displays and sources that support DisplayPort audio)

- Supports native DisplayPort computer connections - no adapter required
- Supports DisplayPort ++ for use with VGA, DVI, or HDMI displays (please see accessories)
- Supports DDC2B monitor detection
- DisplayPort 1.1 Compliant

Hardware

Warranty	2 Years
AV Input	DisplayPort
Ports	2
AV Output	DisplayPort
Audio	Yes
Rack-Mountable	Optional
Industry Standards	DisplayPort 1.1, EDID

Performance

Max Distance	10 m / 33 ft
Maximum Digital Resolutions	2560x1600 @ 60Hz
Wide Screen Supported	Yes

Connector(s)

Connector A	DisplayPort (20 pin)
Connector B	DisplayPort (20 pin)

Special Notes / Requirements


Note	Audio support requires source (PC) and display to both support audio pass through
------	-----------------------------------------------------------------------------------

Indicators

LED Indicators	Green - Online and Display indicator (One LED per port)
----------------	---------------------------------------------------------

Power

Power Source	AC Adapter Included
--------------	---------------------

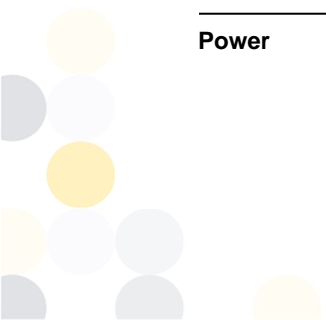

Input Voltage	110V-240V AC
Input Current	0.5A
Output Voltage	5 DC
Output Current	2A
Center Tip Polarity	Positive
Plug Type	M
Power Consumption (In Watts)	10

Environmental

Operating Temperature	0C to 40C (32F to 104F)
Storage Temperature	-20C to 60C (-4F to 140F)
Humidity	0~80% RH


Physical Characteristics

Color	Black
Material	Aluminum
Product Length	5.2 in [13.1 cm]
Product Width	2.6 in [65 mm]
Product Height	1.0 in [26 mm]
Weight of Product	17.6 oz [500 g]

Packaging Information

Package Length	10.6 in [27 cm]
Package Width	7.3 in [18.6 cm]
Package Height	3.1 in [80 mm]
Shipping (Package) Weight	21.2 oz [600.0 g]

 What's in the Box



Included in Package	2 Port DisplayPort Switch
	IR Remote Control
	Universal Power Adapter (US/UK/EU/AUS)
	Manual

****Product appearance and specifications are subject to change without notice.***

